




角先開形端子 (A形)

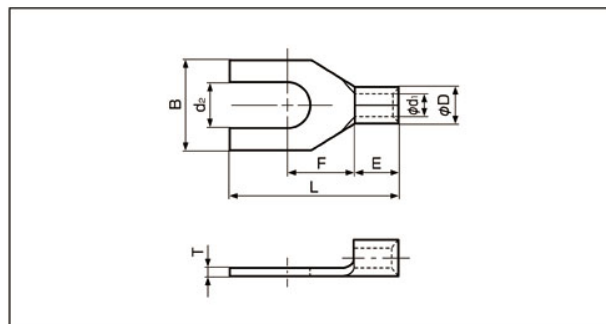

UL LISTED E42024 LR20812

形番	規格	寸法(mm)								適用電線範囲			適用圧着工具			1箱 入数 (個)
		d2	B	L	F	E	φD	φd1	T	単線(mm)	撚線(mm ²)	AWG(#)	手動	空気圧式	油圧式	
0.5-2A	UL E42024 LR20812	2.2	4.6	12.8	4.5	4.0	2.0	1.0	0.5	0.35 }	0.2 }	26 }	YHT-2622	YA-1, YA-2 YAT-1A YAT-2A YAD-1A, YAD-2A	BCT-0514	1,000
0.5-3A	3.2	5.0	12.5	6.0												
0.5-3.7A	3.7	6.4	15.0	7.7												
0.5-4A	4.3	7.0	16.2	6.3												
1.25-C3A	UL E42024 LR20812	3.2	5.6	15.8	6.3	4.8	3.4	1.7	0.8	0.57 }	0.25 }	22 }	YHT-2210	YA-1 YA-2 YAT-1A YAT-2A YAD-1A YAD-2A YA-4 YAT-4A YAD-4A	BCT-0514	1,000
1.25-B3A	5.8															
1.25-M3A	6.35		16.0	8.0												
1.25-C3.5A	5.6	15.8	6.3													
1.25-B3.5A	5.8															
1.25-N3A	6.2															
1.25-YS3A	6.4	15.4														
1.25-S3A	7.2	15.8														
1.25-P3A	7.5	13.8	5.5													
1.25-YS4A	6.4	15.4	6.3													
1.25-S4A	7.2	15.8	6.3													
1.25-4A	8.5			7.0												
1.25-S5A	7.2	15.8	6.3													
1.25-M5A	5.3	8.5	7.0													
1.25-5A	9.5															
1.25-6A	6.4	12.0	22.0	11.0												
2-N3A	UL E42024 LR20812	3.2	5.9	15.8	6.3	4.8	4.1	2.3	0.8	1.14 }	1.04 }	16 }	YHT-2210	YA-1 YA-2 YAT-1A YAT-2A YAD-1A YAD-2A YA-4 YAT-4A YAD-4A	BCT-0514	1,000
2-M3A	6.0		14.5	5.0												
2-C3.5A	5.6		15.8	6.3												
2-YS3A	6.4	15.4	6.5													
2-S3A	7.2	16.0														
2-3A	8.5	16.8	7.3													
2-YS4A	6.4	15.4	6.3													
2-YM4A	6.8	16.0	6.5													
2-S4A	7.2															
2-4A	8.5	16.8	7.3													
2-M5A	5.3	9.5	7.5													
2-5A	9.5															
2-6A	6.4	12.0	22.0	11.0												
5.5-S3A	UL E42024 LR20812	3.7	7.2	19.5	7.5	6.8	5.6	3.4	1.0	1.82 }	2.63 }	12 }	YHT-2210	YA-1 YA-2 YAT-1A, YAT-2A YAD-1A, YAD-2A YA-4 YAT-4A, YAD-4A	BCT-0514	500
5.5-3A	9.5															
5.5-S4A	4.3	9.5														
5.5-4A	5.3	9.5														
5.5-5A	6.4	13.5	25.5	12.2												
5.5-6A	8.4															

注1) 100個入をご用意している製品もあります。詳細は弊社までお問い合わせください。

注2) 本製品の中には多少納期を要するものもあります。