



複列アンギュラ玉軸受

d 10 ~ (40) mm

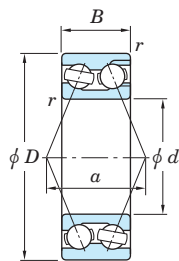

入れ溝付き(32,33系列)

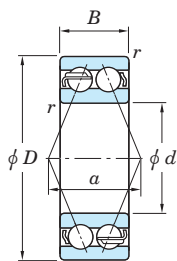

開放形



Z



ZZ

シールド形



RS



2RS

接触シールド形

入れ溝なし(52,53系列)

主要寸法 (mm)				基本定格荷重 (kN)				疲労限荷重 (kN)		許容回転速度 (min^{-1})		
d	D	B	r (最小)	(開放形)		(シールド・シールド形)		(開放形)	〔シールド・シールド形〕	グリース潤滑 油潤滑		
				C_r	C_{0r}	C_r	C_{0r}			(開放形)	(RS, 2RS)	(開放形) Z
10	30	14.3	0.6	9.15	5.35	—	—	0.280	—	15 000	—	20 000
	12	32	15.9	0.6	12.1	7.15	—	—	0.370	—	14 000	—
15	35	15.9	0.6	12.1	7.45	—	—	0.390	—	12 000	—	16 000
	42	19	1	19.0	11.9	—	—	0.610	—	10 000	—	14 000
17	40	17.5	0.6	17.2	10.8	—	—	0.560	—	11 000	—	14 000
	40	17.5	0.6	16.5	8.15	15.9	8.35	0.420	0.430	11 000	11 000	14 000
	47	22.2	1	23.0	17.1	—	—	0.760	—	9 400	—	13 000
20	47	20.6	1	21.5	15.0	—	—	0.770	—	9 000	—	12 000
	47	20.6	1	24.6	12.5	20.0	10.8	0.640	0.560	8 800	8 800	12 000
	52	22.2	1.1	26.0	18.4	—	—	0.950	—	8 200	—	11 000
	52	22.2	1.1	30.9	15.0	24.7	12.8	0.780	0.660	8 300	8 300	11 000
25	52	20.6	1	23.7	18.2	—	—	0.940	—	7 800	—	10 000
	52	20.6	1	26.7	14.8	23.6	13.8	0.760	0.710	7 700	7 700	10 000
	62	25.4	1.1	36.2	26.5	—	—	1.35	—	6 800	—	9 100
	62	25.4	1.1	40.9	20.8	34.3	18.5	1.05	0.960	6 900	6 900	9 200
30	62	23.8	1	34.1	27.0	—	—	1.40	—	6 500	—	8 700
	62	23.8	1	37.2	21.3	31.7	18.3	1.10	0.950	6 400	6 400	8 600
	72	30.2	1.1	47.7	36.1	—	—	1.85	—	5 800	—	7 800
	72	30.2	1.1	51.2	28.5	42.9	25.2	1.45	1.30	5 800	5 800	7 700
35	72	27	1.1	46.0	37.5	—	—	1.95	—	5 600	—	7 500
	72	27	1.1	49.0	29.0	39.7	24.6	1.50	1.25	5 500	5 500	7 300
	80	34.9	1.5	60.7	46.8	—	—	2.40	—	5 200	—	7 000
	80	34.9	1.5	64.0	36.2	57.6	32.8	1.85	1.70	5 100	5 100	6 800
40	80	30.2	1.1	52.4	43.9	—	—	2.25	—	5 000	—	6 700
	80	30.2	1.1	55.5	33.6	45.7	29.1	1.75	1.50	5 000	5 000	6 700

[注] 1) d_a の最大値はシールド・シールド形軸受に適用する。