



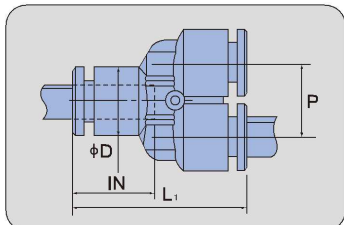

ユニオン Y/UNION Y

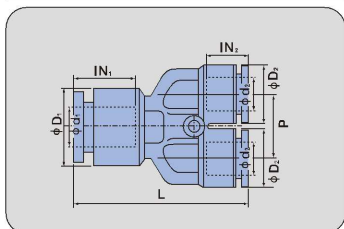

異径ユニオン Y/UNION Y OF DIFFERENT DIAMETERS



ユニオン Y/UNION Y

部品番号 PART NO.	適用チューブ 外径 TUBE O.D. TO BE USED (mm)	φD (mm)	P (mm)	L (mm)	IN (mm)	重量 WEIGHT (g)	最小内径 ORIFICE (mm)	有効断面積 EFFECTIVE SECTIONAL AREA (mm ²)	
								ナイロンチューブ NYLON TUBE	ウレタンチューブ POLYURETHANE TUBE
PYAM- 4-PM	4	10.5	11	32	13	6	2.5	2.4	2.4
PYAM- 6-PM	6	12.5	13	33	14	7	3.5	6.1	6.1
PYAM- 8-PM	8	14.5	16	34	15	9	4.5	14.4	9.7
PYAM-10-PM	10	19	20	49	19	24	7.5	22.0	13.2
PYAM-12-PM	12	22	23	54	21	40	9	28.0	22.0

PYAM-10-PMとPYAM-12-PMに取り付け穴はありません。
There is no bolt hole for fixation in "PYAM-10-PM" and "PYAM-12-PM"

異径ユニオン Y/UNION Y OF DIFFERENT DIAMETERS

部品番号 PART NO.	適用チューブ外径 TUBE O.D. TO BE USED (mm)		φD ₁ (mm)	φD ₂ (mm)	P (mm)	L (mm)	IN ₁ (mm)	IN ₂ (mm)	重量 WEIGHT (g)	最小内径 ORIFICE (mm)	有効断面積 EFFECTIVE SECTIONAL AREA (mm ²)	
	φd ₁	φd ₂									ナイロンチューブ NYLON TUBE	ウレタンチューブ POLYURETHANE TUBE
PYAM- 6- 4-PM	6	4	12.5	10.5	11	33	14	13	6	2.5	10.5	10.5
PYAM- 8- 6-PM	8	6	14.5	12.5	13.3	34.5	15	14	9	3.5	14.4	14.4
PYAM-10- 8-PM	10	8	19	14.5	15.5	42.5	19	15	16	4.5	22.0	19.2
PYAM-12-10-PM	12	10	22	19	20	53.5	21	19	30	7.5	28.0	23.4