

Dimensions in inches (mm)

**Air Side Plugs**

**Accessories for the Coaxial Series**




**ASP-BNC [10017]**

**Features**

Air side plugs are available that connect to Coaxial series.  
Please select the most suitable products for your application.

Connect to	Materials	Voltage: V max. DC	Current: A max.	Temperature Range: °C	REFERENCE	PART NUMBER
<b>BNC</b>	Shell : Nickel Plated Brass Insulation : PTFA	1,500	5	-65 to 165	ASP-BNC	10017
<b>BNC-5kV</b>					ASP-BNC5KV	10001
<b>SHV</b>		5,000	10		ASP-SHV	10002
<b>MHV</b>					ASP-MHV	10001
<b>N</b>					1,000	5
<b>SMA</b>	Shell : Beryllium-Copper Alloy and Gold-Plated Insulation : PTFA	750	3	ASP-SMA	10003	
<b>LEMO</b>	Shell : Brass Chrom Plate Insulation : PEEK®	2,500	4	-50 to 250	ASP-LEMO	10186

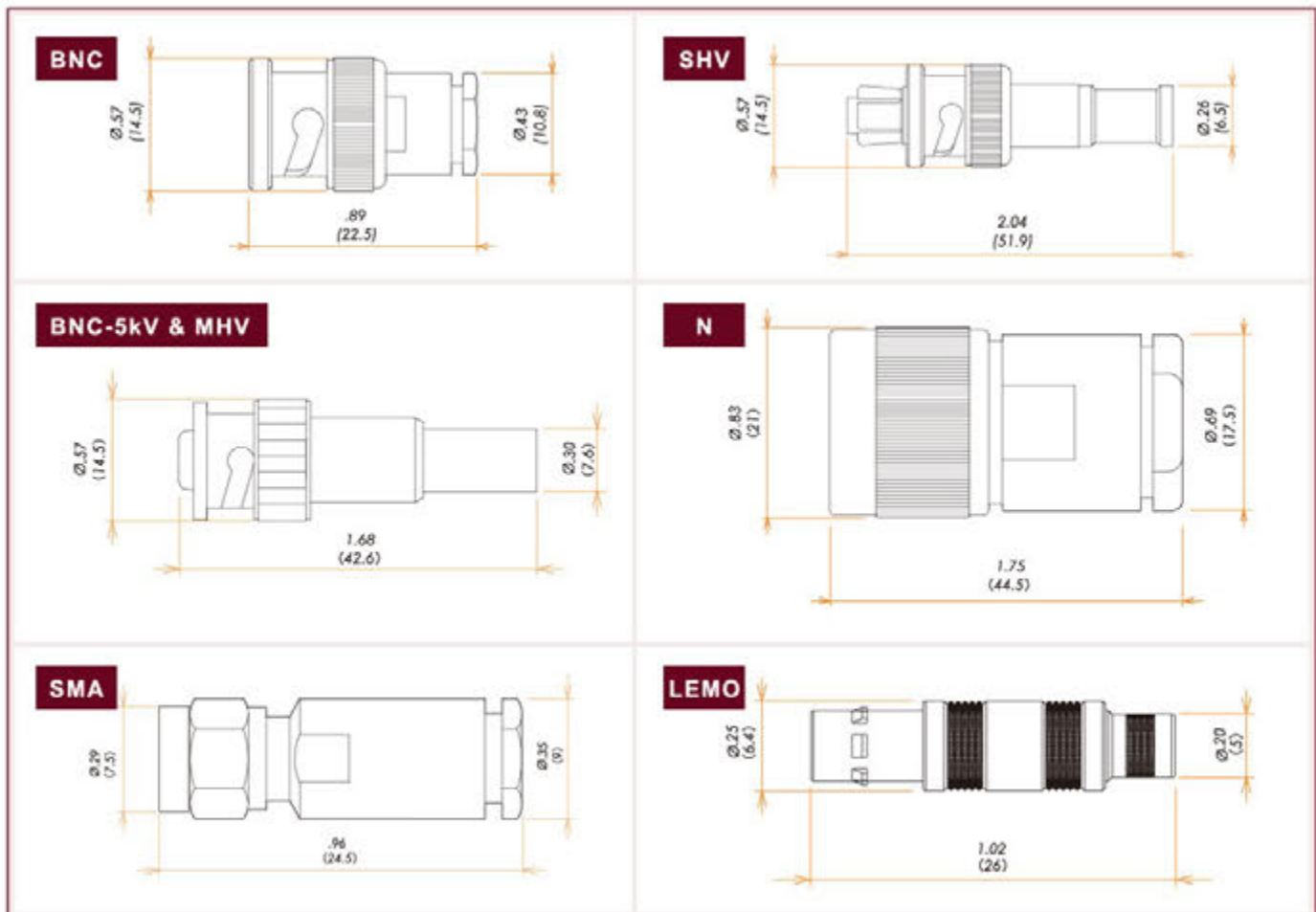

Introduction  
 Table of Contents  
 Glance  
 Coaxial  
 Multipin  
 Thermocouple  
 High Voltage & High Current  
 Isolator  
**Accessories**  
 Custom-made products  
 Technical Data  
 Part number & Reference Index  
 Custom-made Application Sheet  
 Trademarks