


OZ-CP

OZ-CP 材質：アルミ


サイズ		A (mm)	B (mm)	G (mm)	I (mm)	h (mm)	H (mm)
(mm)	(インチ)						
φ38	1½	191	87	36	38	72	119
φ50	2	201	95	49	51	83	135
φ65	2½	213	108	62	64	90	148
φ80	3	267	132	75	77	104	164
φ100	4	296	164	101	103	113	175
φ125	5	322	191	125	127	124	192
φ150	6	454	238	149	152	143	213

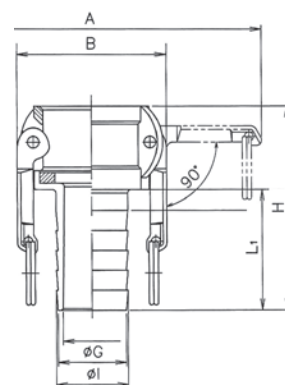

OZ-EP

OZ-EP 材質：アルミ

サイズ		G (mm)	I (mm)	h2 (mm)	L (mm)	H (mm)
(mm)	(インチ)					
φ38	1½	36	38	72	15	123
φ50	2	49	51	83	15	142
φ65	2½	62	64	90	15	154
φ80	3	75	77	104	15	170
φ100	4	101	103	113	15	182
φ125	5	125	127	127	20	200
φ150	6	149	152	143	20	221

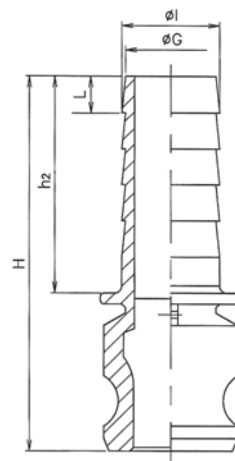

Sカラー付 タケノコニップル

材質：SS400 相当品, SUS304

サイズ	φA (mm)	φB (mm)		C (mm)	D (mm)	E (mm)	φF (mm)	L (mm)
		SS	SUS					
φ38	40.0	34.0	34.0	17.0	85.0	15	54.0	121
φ50	50.8	43.8	44.8	17.0	85.0	15	66.5	135
φ65	63.5	56.5	57.5	17.5	105.0	15	82.5	140
φ75	76.3	67.9	70.3	18.0	108.0	15	97.5	154
φ100	101.6	93.2	93.6	20.0	120.0	16	122.0	174
φ125	127.0	120.0	119.0	18.0	120.0	16	148.0	190
φ150	152.4	143.2	143.2	18.0	134.0	16	174.5	235
φ200	204.4	195.7	190.9	18.0	170.0	19	228.5	280
φ250	254.0	242.0	242.0	20.0	295.0	19	279.5	345
φ300	304.0	289.9	293.0	20.0	345.0	19	330.1	405

(注1) 材質によりφBが異なります。

