




2000 mmの歯面焼入れラック新登場!



共通仕様	
精度等級	KHK R 001 5級*
歯形	並歯
圧力角	20°
材料	S45C
熱処理	歯面レーザ焼入れ
歯面硬度	55 ~ 65HRC
表面処理	黒染

*本製品は、表記精度等級「相当品」です。

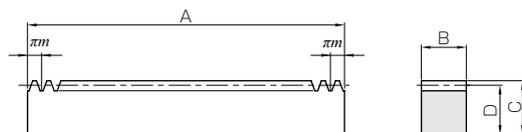

RF

***歯面レーザ焼入れを標準化 価格を抑え、従来のSRFラックより歯面強さを2倍以上アップ!**

カタログ記号	モジュール	歯数	形状	全長				許容伝達力(N)		許容伝達力(kgf)		質量(kg)	価格(円)
				A	B	C	D	曲げ強さ	歯面強さ	曲げ強さ	歯面強さ		
SRF1.5-1000HL SRF1.5-1500HL SRF1.5-2000HL	m1.5	212	RF	999.03	15	20	18.5	2160	961	220	98.0	2.18	16,800
320		1507.96		3.28								25,100	
435		2049.88		4.47								31,500	
SRF2-1000HL SRF2-1500HL SRF2-2000HL	m2	160		1005.31	20	25	23	3830	1730	391	177	3.63	16,900
240		1507.96		5.45								24,200	
326		2048.31		7.40								31,900	
SRF2.5-1000HL SRF2.5-1500HL SRF2.5-2000HL	m2.5	128		1005.31	25	30	27.5	5990	2740	611	280	5.43	17,300
192		1507.96		8.14								25,600	
261		2049.88		11.1								33,700	
SRF3-1000HL SRF3-1500HL SRF3-2000HL	m3	106		999.03	30	35	32	8620	3990	879	407	7.53	20,100
160		1507.96		11.4								29,700	
217		2045.17		15.4								39,700	
SRF4-1000HL SRF4-1500HL SRF4-2000HL	m4	80	1005.31	40	45	41	15300	7220	1560	736	12.9	29,700	
120		1507.96	19.4								43,400		
163		2048.31	26.4								58,300		
SRF5-1000HL SRF5-1500HL SRF5-2000HL	m5	64	1005.31	50	50	45	24000	11400	2440	1170	17.8	46,000	
96		1507.96	26.6								68,300		
130		2042.04	36.1								90,700		
SRF6-1000HL SRF6-1500HL SRF6-2000HL	m6	53	999.03	60	60	54	34500	16700	3520	1700	25.4	63,300	
80		1507.96	38.4								94,300		
108		2035.75	51.8								125,300		

カタログ記号 ●印はJシリーズ(受注生産品)です	モジュール	歯数	形状	全長				取付穴位置寸法				
				A	B	C	D	E	F	G	穴数	使用ねじ
●SRFD1.5-1000HLJ ●SRFD1.5-1500HLJ ●SRFD1.5-2000HLJ	m1.5	212	RD	999.03	15	20	18.5	8	49.51	180	6	M5
320		1507.96		33.98					180	9		
435		2049.88		34.94					180	12		
●SRFD2-1000HLJ ●SRFD2-1500HLJ ●SRFD2-2000HLJ	m2	160		1005.31	20	25	23	10	52.65	180	6	M6
240		1507.96		33.98					180	9		
326		2048.31		34.15					180	12		
●SRFD2.5-1000HLJ ●SRFD2.5-1500HLJ ●SRFD2.5-2000HLJ	m2.5	128		1005.31	25	30	27.5	12	52.65	180	6	M8
192		1507.96		33.98					180	9		
261		2049.88		34.94					180	12		
●SRFD3-1000HLJ ●SRFD3-1500HLJ ●SRFD3-2000HLJ	m3	106		999.03	30	35	32	14	49.51	180	6	M10
160		1507.96		33.98					180	9		
217		2045.17		32.58					180	12		
●SRFD4-1000HLJ ●SRFD4-1500HLJ ●SRFD4-2000HLJ	m4	80	1005.31	40	45	41	18	52.65	180	6	M12	
120		1507.96	33.98					180	9			
163		2048.31	34.15					180	12			
●SRFD5-1000HLJ ●SRFD5-1500HLJ ●SRFD5-2000HLJ	m5	64	1005.31	50	50	45	20	62.65	220	5	M14	
96		1507.96	93.98					220	7			
130		2042.04	31.02					220	10			
●SRFD6-1000HLJ ●SRFD6-1500HLJ ●SRFD6-2000HLJ	m6	53	999.03	60	60	54	23	59.51	220	5	M16	
80		1507.96	93.98					220	7			
108		2035.75	27.88					220	10			