

COMPACT / PORTABLE MODEL



2-WAY power supply



AC adaptor
* AC adaptor sold separately



AA alkaline batteries

Compact and powerful KL-130

- Easy-to-read, 12-digit, 1-line LCD
- Accepts 18, 12, 9 and 6mm tape widths
- 12mm print head / 200 dpi resolution
- Designed logo printing
- Barcode printing
- 534 built-in characters
- AC adaptor (sold separately)

Barcode printing for your business




- EAN-13/EAN-8
- UPC-A/UPC-E
- ITF
- CODE39
- CODABAR (NW-7)

Common features of KL-130 / KL-HD1

8 installed fonts



Prints up to 3 lines
(18mm tape)

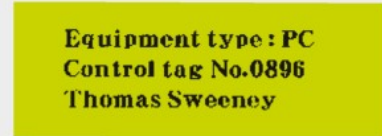

* Actual size



Easy-to-grip vertical shape

Portable label printer KL-HD1

- Accepts 18, 12, 9 and 6mm tape widths
- 12mm print head / 200 dpi resolution
- 8 languages

60 Designed Logo printing

PRICE labels (10)



SIGN labels (20)



WORK labels (10)





ATTENTION labels (20)



* Available in 8 languages (English / Spanish / German / French / Italian / Swedish / Portuguese / Indonesian)

Tape Lineup

* Actual size

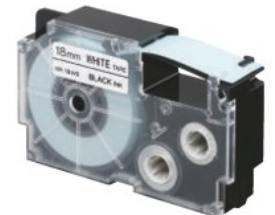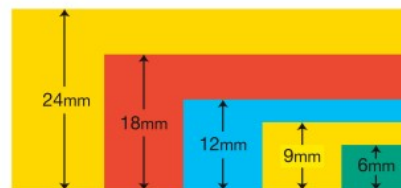

Width	24mm	18mm	12mm	9mm	6mm	
Color Tape [8m]	BLACK on WHITE	XR-24WE1	XR-18WE1	XR-12WE1	XR-9WE1	XR-6WE1
	BLACK on CLEAR	XR-24X1	XR-18X1	XR-12X1	XR-9X1	XR-6X1
	BLACK on RED	XR-24RD1	XR-18RD1	XR-12RD1	XR-9RD1	XR-6RD1
	BLACK on YELLOW	XR-24YW1	XR-18YW1	XR-12YW1	XR-9YW1	XR-6YW1
	BLACK on BLUE	XR-24BU1	XR-18BU1	XR-12BU1	XR-9BU1	—
	BLACK on GREEN	XR-24GN1	XR-18GN1	XR-12GN1	XR-9GN1	XR-6GN1
	BLACK on GOLD	—	XR-18GD1	XR-12GD1	XR-9GD1	—
	BLACK on SILVER	—	XR-18SR1	XR-12SR1	XR-9SR1	—
	RED on WHITE	—	XR-18WER1	XR-12WER1	XR-9WER1	—
	BLUE on WHITE	—	XR-18WEB1	XR-12WEB1	XR-9WEB1	—
Kraft Tape [5m]	BLACK on BEIGE	—	—	XR-12KRBE	—	—
	BEIGE on BLACK	—	—	XR-12KRBK	—	—
	BEIGE on BROWN	—	—	XR-12KRBR	—	—
	BEIGE on GREEN	—	—	XR-12KRGN	—	—
	BEIGE on RED	—	—	XR-12KRRD	—	—
Fluorescent Tape [5.5m]	BLACK on FLUORESCENT PINK	—	XR-18FPK	XR-12FPK	XR-9FPK	—
	BLACK on FLUORESCENT ORANGE	—	XR-18FOE	XR-12FOE	XR-9FOE	—
	BLACK on FLUORESCENT YELLOW	—	XR-18FYW	XR-12FYW	XR-9FYW	—
	BLACK on FLUORESCENT GREEN	—	XR-18FGN	XR-12FGN	XR-9FGN	—
High-Strength Adhesive Tape [8m] - No Residue - Cover up	BLACK on WHITE	XR-24GCWE	XR-18GCWE	XR-12GCWE	XR-9GCWE	XR-6GCWE
	BLACK on YELLOW	XR-24GCIW	XR-18GCIW	XR-12GCIW	XR-9GCIW	XR-6GCIW
Tamper-Evident Tape [5.5m]	BLACK on SILVER	XR-24GCSR	XR-18GCSR	XR-12GCSR	XR-9GCSR	—
Tape for Oily Surfaces [5.5m]	BLACK on SILVER	XR-24SCSR	XR-18SCSR	—	—	—
Cable Flexible Tape [5.5m]	BLACK on WHITE	XR-24TRWE	XR-18TRWE	XR-12TRWE	XR-9TRWE	—
Heat Shrink Tube [2.5m]	BLACK on WHITE	—	XR-18HMWE (Φ5.0mm~Φ11.0mm)	XR-12HMWE	XR-9HMWE (Φ2.5mm~Φ5.0mm)	—
Magnetic Tape [1.5m]	BLACK on WHITE	XR-24JWE	—	—	—	—
	BLACK on YELLOW	XR-24JIW	—	—	—	—
Paper Tape [8m]	BLACK on WHITE	—	XR-18TWE	XR-12TWE	XR-9TWE	—
Iron-On Fabric Tape [3.5m]	BLACK on WHITE	—	—	XR-12VWE	—	—

* For use with KL-P350W