

鋼製握り I, (差込みタイプ) J

Steel Grips I Steel Grips (Insertion Type) J





JIS B2603-1号 相当の鋼製にぎりです。
ねじ込みタイプになっていますので、M5~M16より選定して下さい。



I

J

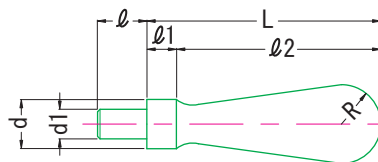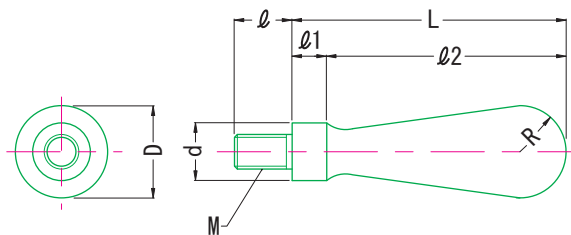

材 鋼材SUM22 Steel

表 クロムメッキ Chrome plated

Unit : mm

品番	D	M	l	L	l1	l2	d	R	(g)
I-13	13	M 5×P0.8	10	35	5	30	8	35	25
I-16	16	M 6×P1.0	13	47	7	40	10	47	45
I-20	20	M 8×P1.25	15	58	8	50	13	58	90
I-25	25	M10×P1.5	18	70	10	60	16	70	175
I-32	32	M12×P1.75	20	93	13	80	20	93	355
I-36	36	M16×P2.0	22	104	14	90	22	104	530

Unit : mm

品番	D	d1	l	L	l1	l2	d	R	(g)
J-13	13	5	10	35	5	30	8	6.5	25
J-16	16	6	13	47	7	40	10	8.0	45
J-20	20	8	15	58	8	50	13	10.0	90
J-25	25	10	18	70	10	60	16	12.5	175
J-32	32	12	20	93	13	80	20	16.0	355
J-36	36	16	22	104	14	90	22	18.0	530

グリップ