


●ATSM




(1袋10個入り)

チューブサイズ
4
6
8
10
12

注文記号

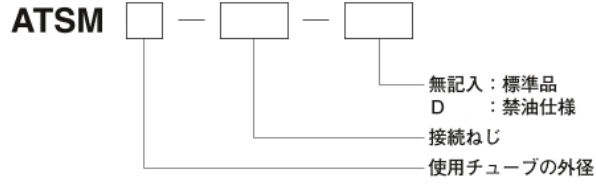

寸法図 (mm)

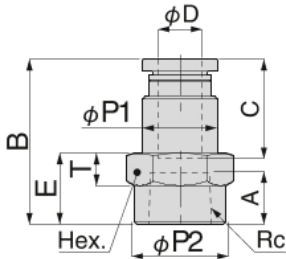めすストレート
ATSM

形式	チューブ外径 φD	Rc	A	B	E	φP1	φP2	C	対辺 Hex.	T	オリフィス径 (φmm)	質量 (g)
ATSM4-01-□	4	Rc1/8	7	23.9	10	9.7	13.8	14.9	14	5	3	13
ATSM4-02-□	4	Rc1/4	9.5	26.9	13	9.7	16.8	14.9	17	6	3	19
ATSM6-01-□	6	Rc1/8	7	26	10	11.8	13.8	17	14	5	5	15
ATSM6-02-□	6	Rc1/4	9.5	29	13	11.8	16.8	17	17	6	5	21
ATSM8-01-□	8	Rc1/8	7	27.2	10	13.7	13.8	18.2	14	5	7	16
ATSM8-02-□	8	Rc1/4	9.5	30.2	13	13.7	16.8	18.2	17	6	7	22
ATSM8-03-□	8	Rc3/8	10.5	31.2	14	13.7	20.8	18.2	21	6.5	7	30
ATSM10-02-□	10	Rc1/4	9.5	32.7	13	17.5	16.8	20.7	17	6	9	28
ATSM10-03-□	10	Rc3/8	10.5	33.7	14	17.5	20.8	20.7	21	6.5	9	37
ATSM12-02-□	12	Rc1/4	9.5	34.8	13.5	20.8	16.8	23.3	21	6.5	11	42
ATSM12-03-□	12	Rc3/8	10.5	36.3	14	20.8	20.8	23.3	21	6.5	11	44

* □⇒無記入（標準品）とD（禁油仕様）の選択