


●ATBLY



(1袋10個入り)


チューブサイズ
4
6
8
10
12

注文記号

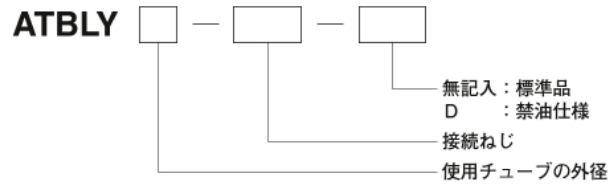

寸法図 (mm)

ブランチエルボワイ
ATBLY

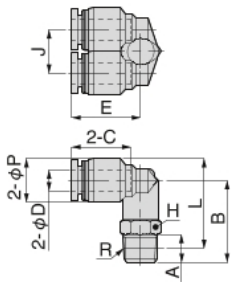

メートルねじタイプ

形式	チューブ外径 φD	R	A	B	L ^注	φP	C	J	E	対辺 H	ねじ径 (φmm)	質量 (g)
ATBLY4-M5-□	4	M5×0.8	2.8	20	22.2	10	14.9	10.3	18.2	10	2.4	11
ATBLY4-M6-□		M6×1	3.8	21							3	
ATBLY4-01-□		R1/8	8	23	24				19.2	14	3.9	20
ATBLY4-02-□		R1/4	11	27	26							
ATBLY6-M5-□	6	M5×0.8	2.8	20.5	24	12.5	17	12.5	19.8	10	2.4	12
ATBLY6-M6-□		M6×1	3.8	21.5							3	
ATBLY6-01-□		R1/8	8	23.5	25.8				21.8	14	4.2	15
ATBLY6-02-□		R1/4	11	29	29.2						5.3	
ATBLY6-03-□	R3/8	12	31.5	31.4	23.8	17	34					
ATBLY8-01-□	8	R1/8	8	25	28.3	14.5	18.1	14.5	22.7	12	5.7	20
ATBLY8-02-□		R1/4	11	29	30.2				23.7	14	7.3	25
ATBLY8-03-□		R3/8	12	32	32.9				24.7	17	37	
ATBLY10-02-□	10	R1/4	11	29.5	32.2	17.5	20.2	17.5	26	14	8	32
ATBLY10-03-□		R3/8	12	32.5	34.9				27	17	9.2	43
ATBLY10-04-□		R1/2	15	37	37.6				28	21	66	
ATBLY12-02-□	12	R1/4	11	29.5	34	21	23.4	21	28.2	14	8	39
ATBLY12-03-□		R3/8	12	33.5	37.7				29.2	17	9.7	51
ATBLY12-04-□		R1/2	15	38	40.3				30.2	21	10.6	74

* □⇒無記入（標準品）とD（禁油仕様）の選択
 * テーパねじタイプのL寸法は、ねじ締付け後の参考寸法です。