


RFC

RB-3

Female Connector
めねじコネクタ



Cd ≤ 75ppm

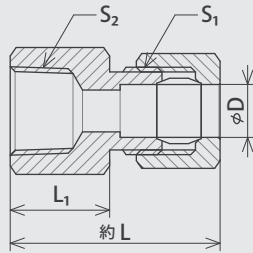

品番	旧品番	呼称 φD × S ₂	対辺寸法		適合管外径 φD	適合ねじ S ₁ (G)	適用ねじ S ₂ (Rc)	寸法情報		
			本体	ナット				約L	L ₁	最小穴径
RFC 03818	RP-54	3 × 1/8	14	12	3.0	1/8	1/8	26.0	12.0	2.8
RFC 03828		3 × 1/4	17	12	3.0	1/8	1/4	29.0	15.0	2.8
RFC 04818	RP-55	4 × 1/8	14	12	4.0	1/8	1/8	26.0	12.0	3.0
RFC 04828		4 × 1/4	17	12	4.0	1/8	1/4	29.0	15.0	3.0
RFC 05818	RP-56	5 × 1/8	14	12	5.0	1/8	1/8	26.0	12.0	4.0
RFC 05828		5 × 1/4	17	12	5.0	1/8	1/4	29.0	15.0	4.0
Ⓟ RFC 06818	RP-312	6 × 1/8	14	16	6.0	1/4	1/8	30.0	12.0	5.0
Ⓟ RFC 06828	RP-313	6 × 1/4	17	16	6.0	1/4	1/4	33.0	15.0	5.0
Ⓟ RFC 06838		6 × 3/8	22	16	6.0	1/4	3/8	37.0	19.0	5.0
Ⓟ RFC 08818		8 × 1/8	14	16	8.0	1/4	1/8	30.0	12.0	6.5
Ⓟ RFC 08828	RP-315	8 × 1/4	17	16	8.0	1/4	1/4	33.0	15.0	6.5
Ⓟ RFC 08838	RP-316	8 × 3/8	22	16	8.0	1/4	3/8	37.0	19.0	6.5
Ⓟ RFC 10828		10 × 1/4	19	19	10.0	3/8	1/4	35.0	15.0	8.0
Ⓟ RFC 10838	RP-318	10 × 3/8	22	19	10.0	3/8	3/8	39.0	19.0	8.0
Ⓟ RFC 10848		10 × 1/2	27	19	10.0	3/8	1/2	42.0	22.0	8.0
Ⓟ RFC 12838		12 × 3/8	22	24	12.0	1/2	3/8	43.0	19.0	10.0
Ⓟ RFC 12848	RP-319	12 × 1/2	27	24	12.0	1/2	1/2	46.0	22.0	10.0
RFC 14838		14 × 3/8	22	24	14.0	1/2	3/8	44.0	19.0	10.0
RFC 14848	RP-57	14 × 1/2	27	24	14.0	1/2	1/2	47.0	22.0	12.0
RFC 15838		15 × 3/8	24	27	15.0	5/8	3/8	46.0	19.0	12.0
RFC 15848		15 × 1/2	27	27	15.0	5/8	1/2	49.0	22.0	12.0
RFC 16838		16 × 3/8	24	27	16.0	5/8	3/8	46.0	19.0	12.0
RFC 16848		16 × 1/2	27	27	16.0	5/8	1/2	49.0	22.0	12.0
RFC 81818	RP-311	1/8 × 1/8	14	12	1/8	1/8	1/8	26.0	12.0	2.8
RFC 81828		1/8 × 1/4	17	12	1/8	1/8	1/4	29.0	15.0	2.8
Ⓟ RFC 82818		1/4 × 1/8	14	16	1/4	1/4	1/8	30.0	12.0	5.0
Ⓟ RFC 82828	RP-314	1/4 × 1/4	17	16	1/4	1/4	1/4	33.0	15.0	5.0
Ⓟ RFC 82838		1/4 × 3/8	22	16	1/4	1/4	3/8	37.0	19.0	5.0
Ⓟ RFC 83828		3/8 × 1/4	19	19	3/8	3/8	1/4	36.0	15.0	8.0
Ⓟ RFC 83838	RP-317	3/8 × 3/8	22	19	3/8	3/8	3/8	40.0	19.0	8.0
Ⓟ RFC 83848		3/8 × 1/2	27	19	3/8	3/8	1/2	43.0	22.0	8.0
Ⓟ RFC 84838		1/2 × 3/8	22	24	1/2	1/2	3/8	44.0	19.0	10.0
Ⓟ RFC 84848	RP-320	1/2 × 1/2	27	24	1/2	1/2	1/2	47.0	22.0	10.0
RFC 85838		5/8 × 3/8	24	27	5/8	5/8	3/8	46.0	19.0	12.0
RFC 85848		5/8 × 1/2	27	27	5/8	5/8	1/2	49.0	22.0	12.0

Ⓟ マークのついた製品には、なまし銅管等を接続するためのインサートリング（ピン）の設定があります。P.22 をご参照ください。