


RML

Ⓜ LBT

Male Elbow Connector
おねじエルボコネクタ



Cd ≤ 75ppm

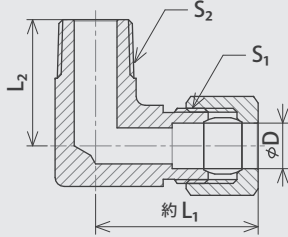

品番	旧品番	呼称 φD × S ₂	対辺寸法		適合管外径 φD	適合ねじ S ₁ (G)	適用ねじ S ₂ (R)	寸法情報		
			本体	ナット				約 L ₁	L ₂	最小穴径
RML 03818	RP-84	3 × 1/8	12	12	3.0	1/8	1/8	25.0	20.0	2.8
RML 03828		3 × 1/4	16	12	3.0	1/8	1/4	27.0	25.0	2.8
RML 04818	RP-85	4 × 1/8	12	12	4.0	1/8	1/8	25.0	20.0	3.0
RML 04828		4 × 1/4	16	12	4.0	1/8	1/4	27.0	25.0	3.0
RML 05818	RP-86	5 × 1/8	12	12	5.0	1/8	1/8	25.0	20.0	4.0
RML 05828		5 × 1/4	16	12	5.0	1/8	1/4	27.0	25.0	4.0
Ⓟ RML 06818	RP-810	6 × 1/8	16	16	6.0	1/4	1/8	31.0	22.0	5.0
Ⓟ RML 06828	RP-801	6 × 1/4	16	16	6.0	1/4	1/4	31.0	25.0	5.0
Ⓟ RML 06838	RP-801A	6 × 3/8	19	16	6.0	1/4	3/8	33.0	28.0	5.0
Ⓟ RML 08818	RP-803A	8 × 1/8	16	16	8.0	1/4	1/8	31.0	22.0	5.0
Ⓟ RML 08828	RP-803	8 × 1/4	16	16	8.0	1/4	1/4	31.0	25.0	6.5
Ⓟ RML 08838	RP-804	8 × 3/8	19	16	8.0	1/4	3/8	33.0	28.0	6.5
Ⓟ RML 10828	RP-806A	10 × 1/4	19	19	10.0	3/8	1/4	35.0	27.0	6.5
Ⓟ RML 10838	RP-806	10 × 3/8	19	19	10.0	3/8	3/8	35.0	28.0	8.0
Ⓟ RML 10848		10 × 1/2	24	19	10.0	3/8	1/2	38.0	34.0	8.0
Ⓟ RML 12838	RP-87	12 × 3/8	24	24	12.0	1/2	3/8	42.0	31.0	9.5
Ⓟ RML 12848	RP-807	12 × 1/2	24	24	12.0	1/2	1/2	42.0	34.0	10.0
RML 14838		14 × 3/8	24	24	14.0	1/2	3/8	43.0	31.0	9.5
RML 14848	RP-89	14 × 1/2	24	24	14.0	1/2	1/2	43.0	34.0	12.0
RML 15838		15 × 3/8	24	27	15.0	5/8	3/8	45.0	31.0	9.5
RML 15848	RP-90	15 × 1/2	24	27	15.0	5/8	1/2	45.0	34.0	12.0
RML 16838		16 × 3/8	24	27	16.0	5/8	3/8	45.0	31.0	9.5
RML 16848	RP-91	16 × 1/2	24	27	16.0	5/8	1/2	45.0	34.0	12.0
RML 81818	RP-809	1/8 × 1/8	12	12	1/8	1/8	1/8	25.0	20.0	2.8
RML 81828		1/8 × 1/4	16	12	1/8	1/8	1/4	27.0	25.0	2.8
Ⓟ RML 82818	RP-802A	1/4 × 1/8	16	16	1/4	1/4	1/8	31.0	22.0	5.0
Ⓟ RML 82828	RP-802	1/4 × 1/4	16	16	1/4	1/4	1/4	31.0	25.0	5.0
Ⓟ RML 82838	RP-804A	1/4 × 3/8	19	16	1/4	1/4	3/8	33.0	28.0	5.0
Ⓟ RML 83828	RP-805A	3/8 × 1/4	19	19	3/8	3/8	1/4	36.0	27.0	6.5
Ⓟ RML 83838	RP-805	3/8 × 3/8	19	19	3/8	3/8	3/8	36.0	28.0	8.0
Ⓟ RML 83848		3/8 × 1/2	24	19	3/8	3/8	1/2	39.0	34.0	8.0
Ⓟ RML 84838	RP-88	1/2 × 3/8	24	24	1/2	1/2	3/8	43.0	31.0	9.5
Ⓟ RML 84848	RP-808	1/2 × 1/2	24	24	1/2	1/2	1/2	43.0	34.0	10.0
RML 85838		5/8 × 3/8	24	27	5/8	5/8	3/8	45.0	31.0	9.5
RML 85848	RP-925	5/8 × 1/2	24	27	5/8	5/8	1/2	45.0	34.0	12.0

Ⓟ マークのついた製品には、なまし銅管等を接続するためのインサートリング（ピン）の設定があります。P.22をご参照ください。