


HTF

Ⓜ HF

Hose Socket
ホースソケット

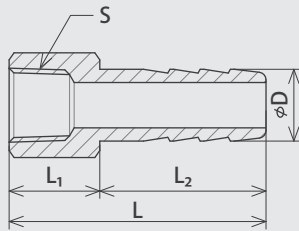

| 品番 | 旧品番 | 呼称 φD × S | 対辺寸法 | ホース口外径 φD | 適用ねじ S(Rc) | 寸法情報 | | | |
|-----------|-------|--------------|------|--------------|---------------|------|----------------|----------------|----------|
| | | | | | | L | L ₁ | L ₂ | 最小 穴径 |
| HTF 01818 | NH-10 | 5.0 × 1/8 | 12 | 5.0 | 1/8 | 30.0 | 12.0 | 18.0 | 2.8 |
| HTF 01828 | | 5.0 × 1/4 | 16 | 5.0 | 1/4 | 33.0 | 15.0 | 18.0 | 2.8 |
| HTF 02818 | NH-11 | 6.5 × 1/8 | 12 | 6.5 | 1/8 | 30.0 | 12.0 | 18.0 | 3.5 |
| HTF 02828 | | 6.5 × 1/4 | 16 | 6.5 | 1/4 | 33.0 | 15.0 | 18.0 | 3.5 |
| HTF 03818 | NH-12 | 8.0 × 1/8 | 12 | 8.0 | 1/8 | 34.0 | 12.0 | 22.0 | 5.0 |
| HTF 03828 | | 8.0 × 1/4 | 16 | 8.0 | 1/4 | 37.0 | 15.0 | 22.0 | 5.0 |
| HTF 03838 | | 8.0 × 3/8 | 19 | 8.0 | 3/8 | 38.0 | 16.0 | 22.0 | 5.0 |
| HTF 04818 | NH-13 | 9.5 × 1/8 | 12 | 9.5 | 1/8 | 34.0 | 12.0 | 22.0 | 6.0 |
| HTF 04828 | NH-16 | 9.5 × 1/4 | 16 | 9.5 | 1/4 | 37.0 | 15.0 | 22.0 | 6.0 |
| HTF 04838 | NH-21 | 9.5 × 3/8 | 19 | 9.5 | 3/8 | 38.0 | 16.0 | 22.0 | 6.0 |
| HTF 05818 | NH-14 | 10.0 × 1/8 | 12 | 10.0 | 1/8 | 34.0 | 12.0 | 22.0 | 6.0 |
| HTF 05828 | NH-17 | 10.0 × 1/4 | 16 | 10.0 | 1/4 | 37.0 | 15.0 | 22.0 | 6.0 |
| HTF 05838 | NH-22 | 10.0 × 3/8 | 19 | 10.0 | 3/8 | 38.0 | 16.0 | 22.0 | 6.0 |
| HTF 06818 | NH-15 | 11.0 × 1/8 | 12 | 11.0 | 1/8 | 37.0 | 12.0 | 25.0 | 7.0 |
| HTF 06828 | NH-18 | 11.0 × 1/4 | 16 | 11.0 | 1/4 | 40.0 | 15.0 | 25.0 | 7.0 |
| HTF 06838 | NH-23 | 11.0 × 3/8 | 19 | 11.0 | 3/8 | 41.0 | 16.0 | 25.0 | 7.0 |
| HTF 07828 | NH-19 | 12.0 × 1/4 | 16 | 12.0 | 1/4 | 40.0 | 15.0 | 25.0 | 7.5 |
| HTF 07838 | NH-24 | 12.0 × 3/8 | 19 | 12.0 | 3/8 | 41.0 | 16.0 | 25.0 | 7.5 |
| HTF 07848 | NH-27 | 12.0 × 1/2 | 24 | 12.0 | 1/2 | 45.0 | 20.0 | 25.0 | 7.5 |
| HTF 08828 | NH-20 | 12.7 × 1/4 | 16 | 12.7 | 1/4 | 40.0 | 15.0 | 25.0 | 8.0 |
| HTF 08838 | NH-25 | 12.7 × 3/8 | 19 | 12.7 | 3/8 | 41.0 | 16.0 | 25.0 | 8.0 |
| HTF 08848 | NH-28 | 12.7 × 1/2 | 24 | 12.7 | 1/2 | 45.0 | 20.0 | 25.0 | 8.0 |
| HTF 09838 | NH-26 | 14.0 × 3/8 | 19 | 14.0 | 3/8 | 51.0 | 16.0 | 35.0 | 9.0 |
| HTF 09848 | NH-29 | 14.0 × 1/2 | 24 | 14.0 | 1/2 | 55.0 | 20.0 | 35.0 | 9.0 |
| HTF 10838 | | 16.0 × 3/8 | 19 | 16.0 | 3/8 | 51.0 | 16.0 | 35.0 | 10.0 |
| HTF 10848 | NH-30 | 16.0 × 1/2 | 24 | 16.0 | 1/2 | 55.0 | 20.0 | 35.0 | 10.0 |

ホース継手