


THL

ⓑ AHL-S

Swivel Elbow (Type H)
旋回エルボ (ホース口式)



Cd ≤ 75ppm

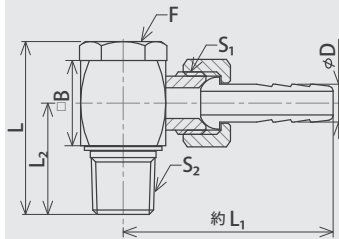

品番	旧品番	呼称 φD × S ₂	寸法		適合管外径 φD	適合ねじ S ₁ (G)	適用ねじ S ₂ (R)	寸法情報		
			F	□B				L	約 L ₁	L ₂
THL 01818	NH-2001	5.0×1/8	12	14	5.0	1/8	1/8	30.0	32.0	19.0
THL 02818	NH-2002	6.5×1/8	12	14	6.5	1/8	1/8	30.0	36.5	19.0
THL 03818	NH-2003	8.0×1/8	16	18	8.0	1/4	1/8	33.5	43.5	20.5
THL 03828	NH-2004	8.0×1/4	16	18	8.0	1/4	1/4	36.5	43.5	23.5
THL 04828	NH-2005	9.5×1/4	19	22	9.5	3/8	1/4	40.5	49.0	25.5
THL 04838	NH-2008	9.5×3/8	19	22	9.5	3/8	3/8	41.5	49.0	26.5
THL 05828	NH-2006	10.0×1/4	19	22	10.0	3/8	1/4	40.5	50.5	25.5
THL 05838	NH-2009	10.0×3/8	19	22	10.0	3/8	3/8	41.5	50.5	26.5
THL 06828	NH-2007	11.0×1/4	19	22	11.0	3/8	1/4	40.5	52.0	25.5
THL 06838	NH-2010	11.0×3/8	19	22	11.0	3/8	3/8	41.5	52.0	26.5
THL 07838	NH-2011	12.0×3/8	24	26	12.0	1/2	3/8	47.0	58.0	29.0
THL 07848	NH-2013	12.0×1/2	24	26	12.0	1/2	1/2	50.0	58.0	32.0
THL 08838	NH-2012	12.7×3/8	24	26	12.7	1/2	3/8	47.0	58.5	29.0
THL 08848	NH-2014	12.7×1/2	24	26	12.7	1/2	1/2	50.0	58.5	32.0
THL 09848	NH-2015	14.0×1/2	24	26	14.0	1/2	1/2	50.0	67.0	32.0


TSL

ⓑ LF-2S

Swivel Elbow (Type S)
旋回エルボ (ねじ込み式)



Cd ≤ 75ppm

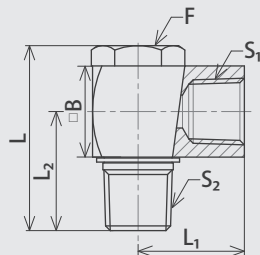

品番	旧品番	呼称 S ₁ × S ₂	寸法		適用ねじ		寸法情報		
			F	□B	S ₁ (Rc)	S ₂ (R)	L	L ₁	L ₂
TSL 81818	SK-2001	1/8×1/8	12	14	1/8	1/8	30.0	16.0	19.0
TSL 82828	SK-2004	1/4×1/4	16	18	1/4	1/4	36.5	21.0	23.5
TSL 83838	SK-2007	3/8×3/8	19	22	3/8	3/8	41.5	24.0	26.5
TSL 84848	SK-2010	1/2×1/2	24	26	1/2	1/2	50.0	29.0	32.0
TSL 81828	SK-2003	1/8×1/4	16	18	1/8	1/4	36.5	21.0	23.5
TSL 82818	SK-2002	1/4×1/8	16	18	1/4	1/8	33.5	21.0	20.5
TSL 82838	SK-2006	1/4×3/8	19	22	1/4	3/8	41.5	24.0	26.5
TSL 83828	SK-2005	3/8×1/4	19	22	3/8	1/4	40.5	24.0	25.5
TSL 83848	SK-2009	3/8×1/2	24	26	3/8	1/2	50.0	29.0	32.0
TSL 84838	SK-2008	1/2×3/8	24	26	1/2	3/8	47.0	29.0	29.0

旋回継手

製品改良のために、形状及び寸法については予告なしに変更することがあります。最新情報については弊社ウェブサイト (www.tsugite.com) にてご確認ください。

Made in Japan.