

Slim type

TIFA7-S Series

Application	No. of pins	Type name	External dimensions (mm)			General mass (g)	Mounting connector	Applicable socket
			A	B	C			
7mm interval								
Flat cable	20	TIFA 720 MHS	80	40	42	92	HIF3BA-20PA-2.54DSA(71)	HIF3BA-20D-2.54R(71)
	26	TIFA 726 MHS	101			108	HIF3BA-26PA-2.54DSA(71)	HIF3BA-26D-2.54R(71)
	30	TIFA 730 MHS	115			124	HIF3BA-30PA-2.54DSA(71)	HIF3BA-30D-2.54R(71)
	34	TIFA 734 MHS	129			141	HIF3BA-34PA-2.54DSA(71)	HIF3BA-34D-2.54R(71)
	40	TIFA 740 MHS	150			162	HIF3BA-40PA-2.54DSA(71)	HIF3BA-40D-2.54R(71)
	50	TIFA 750 MHS	185			199	HIF3BA-50PA-2.54DSA(71)	HIF3BA-50D-2.54R(71)
I/O for board	40	TIFA 740 F360S	150			160	FCN-364P040-AU	FCN-367J040-AU/FW, FCN-367J040-AU/MW
7mm interval, fall prevention screw								
Flat cable	20	TIFA 7Y20 MHS <small>Note</small>	80	40	42	97	HIF3BA-20PA-2.54DSA(71)	HIF3BA-20D-2.54R(71)
	34	TIFA 7Y34 MHS <small>Note</small>	129			141	HIF3BA-34PA-2.54DSA(71)	HIF3BA-34D-2.54R(71)
	40	TIFA 7Y40 MHS <small>Note</small>	150			167	HIF3BA-40PA-2.54DSA(71)	HIF3BA-40D-2.54R(71)
	50	TIFA 7Y50 MHS <small>Note</small>	185			199	HIF3BA-50PA-2.54DSA(71)	HIF3BA-50D-2.54R(71)
I/O for board	40	TIFA 7Y40 F360S <small>Note</small>	150			165	FCN-364P040-AU	FCN-367J040-AU/FW, FCN-367J040-AU/MW

Note: Product built to order.

Standard type


TIFA Series

Application	No. of pins	Type name	External dimensions (mm)			General mass (g)	Mounting connector	Applicable socket
			A	B	C			
7mm interval								
I/O for board	20	TIFA 720 F360	80	45	45	98	FCN-364P024-AU	FCN-367J024-AU/F
Multiple pin square type male	20	TIFA 720 MRP <small>Note</small>	80			98	MR-20RMD2	MR-20F+MR20L
	34	TIFA 734 MRP <small>Note</small>	136			163	MR-34RMD2	MR-34F+MR34L
	50	TIFA 750 MRP <small>Note</small>	195			229	MR-50RMD2	MR-50F+MR50L
Multiple pin square type female	20	TIFA 720 MRS <small>Note</small>	80			98	MR-20RFD2	MR-20M+MR20L
	50	TIFA 750 MRS <small>Note</small>	195			229	MR-50RFD2	MR-50M+MR50L
D sub-connector male	25	TIFA 726 DPH25 <small>Note</small>	101			129	SDBB-25P	HDBB-25S
	37	TIFA 740 DPH37 <small>Note</small>	150			187	SDCB-37P	HDCB-37S
D sub-connector female	25	TIFA 726 DSH25 <small>Note</small>	101			129	SDBB-25S	HDBB-25P
	37	TIFA 740 DSH37 <small>Note</small>	150			187	SDCB-37S	HDCB-37P
7mm interval, fall prevention screw								
I/O for board	20	TIFA 7Y20 F360	80	45	45	98	FCN-364P024-AU	FCN-367J024-AU/F
8.5mm interval								
Flat cable	20	TIFA 820 MH	95	55	51	136	HIF3BA-20PA-2.54DSA(71)	HIF3BA-20D-2.54R(71)
	30	TIFA 830 MH	138			194	HIF3BA-30PA-2.54DSA(71)	HIF3BA-30D-2.54R(71)
	34	TIFA 834 MH	163			232	HIF3BA-34PA-2.54DSA(71)	HIF3BA-34D-2.54R(71)
	40	TIFA 840 MH	180			254	HIF3BA-40PA-2.54DSA(71)	HIF3BA-40D-2.54R(71)
	50	TIFA 850 MH	233			323	HIF3BA-50PA-2.54DSA(71)	HIF3BA-50D-2.54R(71)
I/O for board	20	TIFA 820 F360 <small>Note</small>	95			139	FCN-364P024-AU	FCN-367J024-AU/F
	40	TIFA 840 F360 <small>Note</small>	180			256	FCN-364P040-AU	FCN-367J040-AU/FW, FCN-367J040-AU/MW
Multiple pin square type male	20	TIFA 820 MRP <small>Note</small>	95			139	MR-20RMD2	MR-20F+MR20L
	34	TIFA 834 MRP <small>Note</small>	163			236	MR-34RMD2	MR-34F+MR34L
	50	TIFA 850 MRP <small>Note</small>	233			327	MR-50RMD2	MR-50F+MR50L


Note: Product built to order.



TIFA720MHS

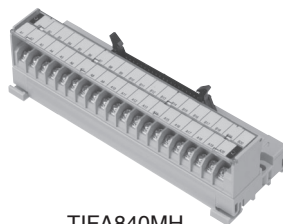

TIFA840MH

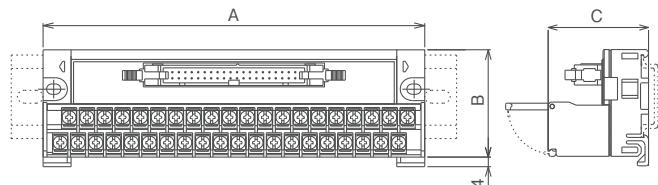

Line-up
Clutch Lock
Terminal Blocks
PLC Interface
Terminal Blocks
Rail Type
Terminal Blocks
Assembly
Terminal Blocks
Special Purpose
Terminal Blocks
Terminal Block Accessories