



Stud terminal block for grounding

TS-CHM Series

Application				Type name	External dimensions (mm)				General mass (g)
					A	B	C	D	
600V	38mm ²	[100A]	4-M8	TS 104 CHM	180	28	23	25	310
	100mm ²	[200A]	3-M10	TS 203 CHM	120	33	30	25	360
	100mm ²	[200A]	4-M10	TS 204 CHM	180	28	30	25	430
	200mm ²	[400A]	4-M12	TS 404 CHM	300	40	35	30	1000

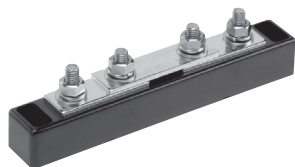

TS 404 CHM

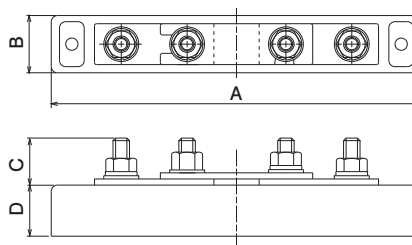


Terminal block for board

TPC Series

Application	No. of pins	Type name	External dimensions (mm)			General mass (g)
			A	B	C	
Terminal interval: 7mm						
250V 1.25mm ² [10A] with M3 wire holder With cover and name sticker	20	TPC 70 20	80	21.6	29.6	105
	26	TPC 70 26	101			140
	30	TPC 70 30	115			160
	34	TPC 70 34	129			185
	36	TPC 70 36	136			200
	40	TPC 70 40	150			210
250V 1.25mm ² [10A] M3, non-loosening screw With cover and name sticker	20	TPC 7Y 20	80	21.6	29.6	105
	40	TPC 7Y 40	150			210
Terminal interval: 8.5mm						
250V 2mm ² [10A] with M3.5 wire holder With cover and name sticker	20	TPC 85 20	95	28.2	35.2	165
	30	TPC 85 30	138			270
	36	TPC 85 36	163			325
	40	TPC 85 40	180			330



TPC 85 40

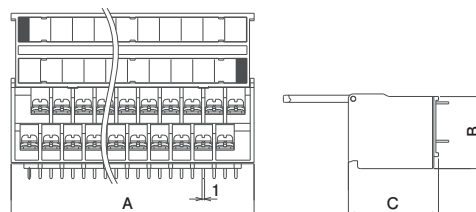

Line-up
Clutch Lock
Terminal Blocks
PLC Interface
Terminal Blocks
Rail Type
Terminal Blocks
Assembly
Terminal Blocks
Special Purpose
Terminal Blocks
Terminal
Block Accessories