


Exposure Type

BS series

Type	Rating			Type name	Dimensions (mm)			General mass (g)
					A	B	C	
Steel case	2P 10A	1 ϕ 100/110V	0.2kW	BS 210B 2	43	89.5	47.5	140
		1 ϕ 200/220V	0.75kW					
	3P 10A	3 ϕ 200/220V	1.5kW	BS 210B 3	43	89.5	47.5	140
		3 ϕ 400/440V	1.5kW					
	2P 15A	1 ϕ 100/110V	0.4kW	BS 215B 2	52	92.5	53.5	190
		1 ϕ 200/220V	1.1kW					
3P 15A	3 ϕ 200/220V	2.2kW	BS 215B 3	52	92.5	53.5	190	
	3 ϕ 400/440V	2.2kW						
2P 30A	1 ϕ 100/110V	0.75kW	BS 230B 2	61	113	54.5	260	
	1 ϕ 200/220V	1.5kW						
3P 30A	3 ϕ 200/220V	3.7kW	BS 230B 3	61	113	54.5	280	
	3 ϕ 400/440V	3.7kW						
Plastic case	2P 15A	1 ϕ 100/110V	0.4kW	BSE 215 2	38	83	41.5	80
		1 ϕ 200/220V	1.1kW					
	3P 15A	3 ϕ 200/220V	2.2kW	BSE 215 3	38	83	41.5	80
		3 ϕ 400/440V	2.2kW					
2P 30A	1 ϕ 100/110V	0.75kW	BSE 230 2	45	93	44.5	100	
	1 ϕ 200/220V	1.5kW						
3P 30A	3 ϕ 200/220V	3.7kW	BSE 230 3	45	93	44.5	110	
	3 ϕ 400/440V	3.7kW						
With fuse base	3P 15A	3 ϕ 200/220V	2.2kW	BSF 215B 3	81	147.5	58.5	450
	3P 30A	3 ϕ 200/220V	3.7kW	BSF 230B 3	97	174.5	58.5	630
For installing on device	2P 10A	1 ϕ 100/110V	0.2kW	BSK 210B 2	92	38	43	150
		1 ϕ 200/220V	0.75kW					
Reversible	2P 15A	1 ϕ 100/110V	0.4kW	BS 315 2	64	164	68	470
		1 ϕ 200/220V	1.1kW					
	3P 15A	3 ϕ 200/220V	2.2kW	BS 315 3	64	164	68	470
Inching type (Normal/Reverse)	3P 15A	3 ϕ 200/220V	2.2kW	BS 315 4 ^{Note}	64	164	68	460
		3 ϕ 400/440V	2.2kW					
	3P 30A	3 ϕ 200/220V	3.7kW	BS 330B 4 ^{Note}	74	176	69.5	450
Inching type (Normal/Stop/Notch)	3P 15A	3 ϕ 200/220V	2.2kW	BS 315 5 ^{Note}	64	164	68	470
		3 ϕ 400/440V	2.2kW					
	3P 30A	3 ϕ 200/220V	3.7kW	BS 330B 5 ^{Note}	74	176	69.5	560
3P 30A	3 ϕ 200/220V	3.7kW	BS 330B 3	74	176	69.5	560	
	3 ϕ 400/440V	3.7kW						

Note: Product built to order

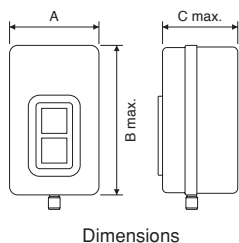

BS 210B 2



BSE 215 2



BSF 215B 3



BSK 210B 2



BS 315

Power Switches

Hoist Push-Button Switches

Operating Push Button Switches

Foot Switches

Liquid Level Relays