



0301 KSS NYLON CABLE TIE

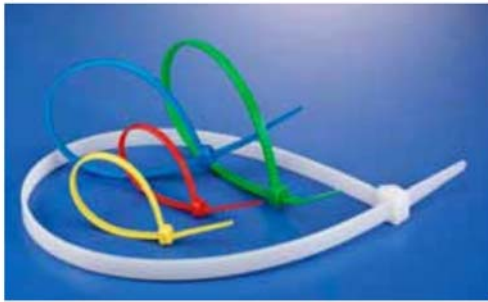

- Material: UL approved Nylon 66, 94V-2, With good tensile strength and insulation, not easy to get aging.
- Color: Standard color is natural, black, other special colors are available upon request.
- Feature: Use to bundle wires, cables, wrapping and get gardening neat and tidy.
- Application: Insert tie into the lock of head and pull out easily to bundle it.

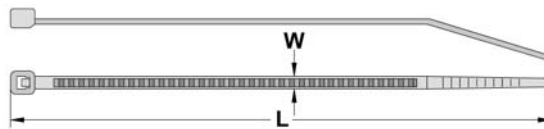

UNIT : mm

Item No.				Length		W	Max.Bundle Dia.	Min LoopTensile Strength		MINIATURE
Natural		Black		mm	inch			lbs	kgs	
100pcs	1000pcs	100pcs	1000pcs							
※CVT-070	CVT-070K	CVT-070B	CVT-070KB	71	2 13/16"	1.6	11	7	3	
CV-060	CV-060K	CV-060B	CV-060KB	63.7	2 1/2"	2.4	11	18	8	
CV-075	CV-075K	CV-075B	CV-075KB	75	3"	2.4	15			
CV-080	CV-080K	CV-080B	CV-080KB	80	3 1/8"	2.5	16			
CV-094	CV-094K	CV-094B	CV-094KB	96	3 3/4"	2.5	21			
CV-100	CV-100K	CV-100B	CV-100KB	100	4"	2.5	22			
※CVT-100	CVT-100K	CVT-100B	CVT-100KB	103	4"	1.95	22			
CV-120S	CV-120SK	CV-120SB	CV-120SKB	120	4 3/4"	2.5	28			
CV-140S	CV-140SK	CV-140SB	CV-140SKB	142	5 1/2"	2.5	35			
CV-150S	CV-150SK	CV-150SB	CV-150SKB	155	6 1/8"	2.5	39			
CV-165	CV-165K	CV-165B	CV-165KB	165	6 1/2"	2.5	43			
CV-200M	CV-200MK	CV-200MB	CV-200MKB	203	8"	2.5	55			
CV-250S	CV-250SK	CV-250SB	CV-250SKB	250	10"	2.5	68			
CV-300M		CV-300MB		300	11 7/8"	2.5	80			
CV-400S		CV-400SB		400	15 3/4"	2.5	116			
CV-120	CV-120K	CV-120B	CV-120KB	120	4 3/4"	3.2	27	40	18	
CV-140	CV-140K	CV-140B	CV-140KB	142	5 1/2"	3.2	34			
CV-150	CV-150K	CV-150B	CV-150KB	150	6"	3.6	36			
CV-180	CV-180K	CV-180B	CV-180KB	180	7"	3.6	46			
※CV-180T	CV-180TK	CV-180TB	CV-180TKB	180	7"	3.6	46			
CV-200S	CV-200SK	CV-200SB	CV-200SKB	203	8"	3.2	53			
CV-200A	CV-200AK	CV-200AB	CV-200AKB	203	8"	3.6	52			
CV-250M	CV-250MK	CV-250MB	CV-250MKB	250	10"	3.6	68			
CV-265	CV-265K	CV-265B	CV-265KB	265	10 1/2"	3.6	73			
CV-292	CV-292K	CV-292B	CV-292KB	292	11 1/2"	3.6	82			
CV-330		CV-330B		330	13"	3.6	93			
CV-368S		CV-368SB		368	14 1/2"	3.6	105			
CV-120L	CV-120LK	CV-120LB	CV-120LKB	120	4 3/4"	4.8	27	50	22	
CV-160L	CV-160LK	CV-160LB	CV-160LKB	160	6 1/4"	4.8	39			
CV-190	CV-190K	CV-190B	CV-190KB	190	7 1/2"	4.8	49			
※CV-190T	CV-190TK	CV-190TB	CV-190TKB	190	7 1/2"	4.8	49			
CV-200	CV-200K	CV-200B	CV-200KB	203	8"	4.6	52			
CV-200D	CV-200DK	CV-200DB	CV-200DKB	203	8"	4.8	52			

※ CVT-070 doesn't have minimum bundle diameter. ※ CV-200T Tail ※ CV-300STZ Tail CV-180T CV-190T