
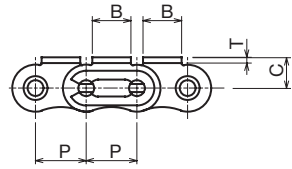
 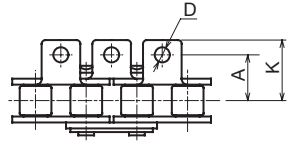


# Roller Chains with Attachments A1-type Attachments

## Order No. Example

### 40-2L A1 240 Links



Chains where attachments are attached to roller chains. Dimensions comply with JIS.  
Can be used as a highly accurate small conveyor type.

Chain No.	Attachment		Plate Thickness T	D	Attachment				Average Tensile Strength kN (kgf)	Maximum Allowable Tension kN (kgf)
	Configuration	Type			A	B	C	K		
40	ALL	A1	1.5	3.6	12.7	9.5	7.9	17.4	17.2 (1,750)	2.75 (280)
50	2L		2.0	5.2	15.9	12.7	10.3	22.3	27.9 (2,850)	4.41 (450)
	3L		2.4	5.2	19.05	15.9	11.9	27.2	39.5 (4,000)	6.28 (640)
60	4L		3.2	6.8	25.40	19.1	15.9	35.2	68.6 (7,000)	10.69 (1,090)
80	6L									

Chain No.	Attachment Attached per Location Approx. Weight g	Approx. Weight kg/m	No. of Links	m	Unit						JL	
					No. in Box (Quantity)	ALL ¥	2L ¥	3L ¥	4L ¥	6L ¥	A1 ¥	
40	1.4	0.61	240L	3	15							
50	3.2	1.01	192L		8							
60	5.6	1.49	160L		5							
80	13.0	2.50	120L		4							



Chain No. Configuration Type Unit and Quantity



Same-day shipping (Unit Only)

\* Products with dimensional cutting are shipped in 3 working days.



\* There are no OL for chains with attachments.  
\* Dimensional cutting products will be charged as a combination of product price with chain cutting fee included.



For continued lubrication and effective anti-corrosion, protect your chains with Kanalon. See P344

