


Rustop Chains

Plated Chains

● Order No. Example

40-N 240 Links
Chain No. **10ft**
3m
Unit

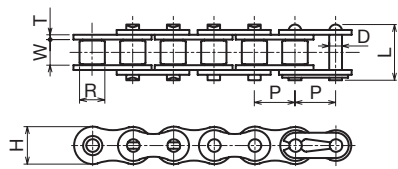

Rustop Chains are glossy and beautiful chains with general corrosion resistance where special plating is implemented on standard steel chains. * They are less expensive than stainless steel chains and are effective especially for environment friendly purposes.

* Their rupture strength is better than stainless steel chains.

Rustop Chains are available for most of the chains with attachments, such as roller chains or double pitch chains. Specify according to application.

Chain No.	Pitch P	Roller Outer Diameter R	Inner Link Inner Width W	Maximum Allowable Weight kN (kgf)	Unit				JL & OL		
					No. of Links	m	No. in Box (Quantity)	¥	¥		No. in Box (Quantity)
									JL	OL	
25-N	6.35	3.30	3.18	0.64(65)	480L	3	50			100	
35-N	9.525	5.08	4.78	1.84(190)	320L	3	20			100	
35-NCS				-	8,000L	76	1			-	
40-N	12.70	7.92	7.95	3.04(310)	240L	3	10			100	
50-N	15.875	10.16	9.53	5.39(550)	192L	3	5			50	
60-N	19.05	11.91	12.70	7.26(740)	160L	3	5			25	
80-RPN	25.40	15.88	15.88	12.7 (1,300)	120L	3	3			20	
C2040-N	25.40	7.92	7.95	2.75(280)	120L	3	10			50	
C2050-N	31.75	10.16	9.53	4.41(450)	96L	3	5			25	
C2060H-N	38.10	11.91	12.70	6.28(640)	80L	3	5			20	



Chain No. Surface Treatment Unit and Quantity



Same-day shipping (Unit Only)

* Products with dimensional cutting are shipped in 3 working days.



- * The D/L/H dimensions are the same as ►► P70 to P71 Standard Roller Chains.
- * Do not use Rustop Chains in places where chains may directly contact food or friction powder may get mixed into food.
- * Dimensional cutting products will be charged as a combination of product price with chain cutting fee included.



For continued lubrication and effective anti-corrosion, protect your chains with Kanalon. See P344

