



# Hollow Pin Chains

● **Order No. Example**  
**40HP-240 Links**  
 Chain No. **10ft**  
**3m**  
 Unit

Standard Hollow Pin Roller Chain

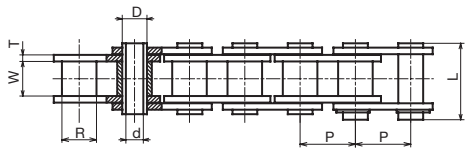

 Double Pitch Hollow Pin Roller Chain




Standard Hollow Pin Roller Chain


Hollow pin chains are chains connected with hollow pins. Attachments can be easily mounted since pins are hollow.

The standards of hollow chains are the same as those of JIS standard roller chains or double pitch roller chains, and thus standard sprockets can be used.

Chain No.		Pitch P	Bushing		Inner Link		Link Plate		Pin			Average	Maximum	Approx.
Type	Roller Shape		Outer Diameter R	Inner Width W	Thickness T	Width H	Outer Diameter D	Inner Diameter d	Length L	Tensile Strength kN (kgf)	Allowable Tension kN (kgf)	Weight kg/m		
40HP	-	12.70	7.92	7.95	1.5	11.7	5.68	4.00	17.5	13.2 (1,350)	1.77 (180)	0.51		
50HP	-	15.875	10.16	9.53	2.0	14.6	7.24	5.12	22.0	20.6 (2,100)	3.14 (320)	0.83		
60HP	-	19.05	11.91	12.70	2.4	17.5	8.37	5.99	27.2	31.4 (3,200)	4.22 (430)	1.24		
C2040HP	S	25.40	7.92	7.95	1.5	11.7	5.68	4.00	17.5	13.2 (1,350)	1.77 (180)	0.46		
C2050HP	S	31.75	10.16	9.53	2.0	14.6	7.24	5.12	22.0	20.6 (2,100)	3.14 (320)	0.76		
C2060HP	S	38.10	11.91	12.70	2.4	17.5	8.37	5.99	27.2	31.4 (3,200)	4.22 (430)	1.12		




and Quantity




### Same-day shipping (Unit Only)


\* Products with dimensional cutting are shipped in 3 working days.



\* Ideal for small conveyors which require replacing attachments, cross rods, etc. (Use examples are as follows). Food manufacturing machines, office machines, packaging machines, agriculture machines, looms, etc.



\* There are no OL for Hollow Pin Chains.  
 \* Dimensional cutting products will be charged as a combination of product price with chain cutting fee included.



For continued lubrication and effective anti-corrosion, protect your chains with Kanalon. See P344

