


 
35SD



SD Single-Double Sprocket

Order No. Example

35SD 20

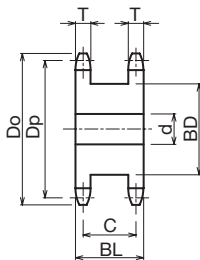

- Chain No.35
- Chain Pitch (P)9.525mm
- Bushing Link Inner Width ... (W)4.78 mm
- Bushing Outside Diameter ... (Dr)5.08 mm
- Tooth Width (T)4.3 mm (C)15.7mm

m Carbon Structural Steel

h High-frequency Hardened Teeth

Type	No. of Teeth	Outer Diameter Do	Pitch Diameter Dp	Shaft Hole Diameter d			Boss Diameter BD	Boss Length BL	Weight kg	¥	Semi-F ¥
				Prepared Hole Product	Minimum	Maximum					
35SD	12	41	36.80	10	11	15	24	20	0.12		
	13	44	39.80	10	11	16	28	20	0.13		
	14	47	42.81	10	11	16	30	20	0.15		
	15	51	45.81	10	11	20	35	20	0.19		
	16	54	48.82	10	11	20	37	20	0.22		
	17	57	51.84	10	11	25	41	20	0.25		
	18	60	54.85	10	11	25	44	20	0.28		
	19	63	57.87	10	11	28	47	20	0.32		
	20	66	60.89	12	13	30	50	20	0.36		
	21	69	63.91	12	13	32	53	20	0.40		
	22	72	66.93	12	13	35	56	20	0.45		
	23	75	69.95	15	16	38	59	20	0.49		
	24	78	72.97	15	16	40	62	20	0.54		
	25	81	76.00	15	16	42	65	20	0.59		
	26	84	79.02	15	16	45	68	20	0.60		
27	87	82.05	15	16	48	71	20	0.69			
28	90	85.07	15	16	50	74	20	0.75			
30	96	91.12	15	16	52	80	20	0.87			



Sprocket No. and Quantity



* Since we also manufacture sizes other than those in the catalog, and machine shaft holes/keys/taps, etc., depending on your request, please contact our company's sales office for details.



Same-day shipping

Postage

* Please refer to P24 to P33 for the Semi-F Series <Complete Product> order method.