



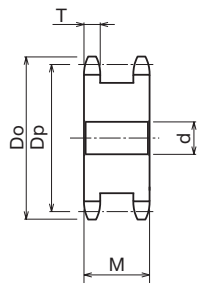

HG80-2A HG High-grade Sprocket with Hardened Teeth Two-row A-type

● Order No. Example

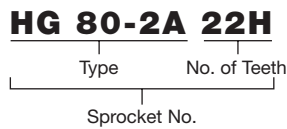

- Chain No.80-2
- Chain Pitch (P)25.4 mm
- Roller Link Inner Width (W)15.88mm
- Roller Outside Diameter (Dr)15.88mm
- Tooth Width (T)14.1 mm (M)43.4mm

-  Carbon Structural Steel
-  High-frequency Hardened Teeth

Type	No. of Teeth	Outer Diameter Do	Pitch Diameter Dp	Shaft Hole Diameter d		Boss Diameter BD	Boss Length BL	Shape	Weight kg	¥	Semi-F ¥
				Prepared Hole Product	Minimum						
HG 80-2A	22H	192	178.48	23	24	150	43.4	Ground Specification	7.49		Series Addition under Discussion
	23H	200	186.54	23	24	159	43.4		8.28		
	24H	208	194.60	23	24	167	43.4		9.04		
	25H	216	202.66	23	24	175	43.4		9.88		
	26H	224	210.72	23	24	183	43.4		10.73		
	27H	233	218.79	23	24	191	43.4		11.61		
	28H	241	226.86	23	24	199	43.4	12.57			
	30H	257	243.00	23	24	215	43.4	14.55			
	32H	273	259.14	28	29	232	43.4	16.66			
	35H	297	283.36	28	29	256	43.4	20.09			
	36H	306	291.43	28	29	264	43.4	21.28			
	38H	322	307.58	28	29	280	43.4	23.84			
	40H	338	323.74	33	34	297	43.4	26.53			
	42H	354	339.89	33	34	313	43.4	29.27			
	44H	370	356.05	33	34	329	43.4	32.31			
	45H	378	364.12	33	34	337	43.4	32.78			
	46H	387	372.20	33	34	345	43.4	35.34			
	48H	403	388.36	33	34	361	43.4	38.56			
50H	419	404.52	33	34	378	43.4	42.05				
60H	500	485.33	33	34	459	43.4	61.04				



Sprocket No. and Quantity



Same-day shipping



* Goods for which the weight of a single item exceeds 30kg With Sagawa Express/Yamato Transport, products cannot be shipped at any time.



* Since we also manufacture sizes other than those in the catalog, and machine shaft holes/keys/taps, etc., depending on your request, please contact our company's sales office for details.