

 
NK120B/NK120C




Standard Sprocket B-type/C-type

Order No. Example

NK120B 20



Ground Specification Welded Specification

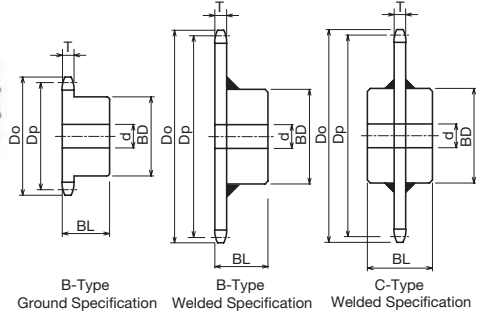

- ChainNo.120
- Chain Pitch(P)38.10mm
- Roller Link Inner Width(W)25.40mm
- Roller Outside Diameter(Dr)22.23mm
- Tooth Width(T)23.5 mm

Sprocket No.		Outer Diameter	Pitch Diameter	Shaft Hole Diameter d		Boss Diameter	Boss Length	Shape	Material	Weight kg	¥	Semi-F ¥
Type	No. of Teeth	Do	Dp	Prepared Hole Product	Minimum	Maximum	BD	BL				
NK120B	10	140	123.29	23	24	51	78	56	Ground Specification	h m Carbon Structural Steel High-frequency Hardened Teeth	3.20	
	11	153	135.24	25	26	60	91	56			4.00	
	12	165	147.21	25	26	66	98	56			4.80	
	13	177	159.20	25	26	66	98	56			5.30	
	14	190	171.22	25	26	75	107	56			6.30	
	15	202	183.25	25	26	80	117	63			7.80	
	16	214	195.29	25	26	80	117	63			8.40	
	17	227	207.35	25	26	80	117	63			9.10	
	18	239	219.41	25	26	80	117	63			9.90	
	19	251	231.48	25	26	80	117	63			10.70	
	20	263	243.55	25	26	89	127	63	12.10			
	21	276	255.63	25	26	89	127	63	13.00			
	22	288	267.72	26	27	89	127	63	13.40			
	23	300	279.80	26	27	89	127	63	14.50			
	24	312	291.90	26	27	89	127	63	15.20			
	25	324	303.99	26	27	89	127	63	16.20			
	26	337	316.09	26	27	89	127	63	17.20			
	28	361	340.29	26	27	95	137	71	20.90	m Common Steel		
	30	385	364.50	26	27	95	137	71	23.20			
	32	410	388.71	30	31	95	137	71	25.70			
	33	422	400.82	30	31	95	137	71	28.40			
34	434	412.93	30	31	95	137	71	29.00				
35	446	425.04	30	31	95	137	71	29.70				
36	458	437.15	30	31	95	137	71	32.00				
38	483	461.38	30	31	95	137	71	35.00				
40	507	485.60	30	31	103	147	80	38.20				
42	531	509.83	30	31	103	147	80	42.00				
45	568	546.19	30	31	103	147	80	47.60				
48	604	582.54	30	31	103	147	80	53.00				
50	628	606.78	30	31	103	147	80	58.00				
NK120C	54	677	655.26	30	31	103	147	100	Welded Specification	m Common Steel	65.20	
	60	750	727.99	30	31	103	167	100			78.00	



Sprocket No. and Quantity



* Goods for which the weight of a single item exceeds 30kg With Sagawa Express/Yamato Transport, products cannot be shipped at any time.



Same-day shipping



* Since we also manufacture sizes other than those in the catalog, and machine shaft holes/keys/taps, etc., depending on your request, please contact our company's sales office for details.

* Please refer to P24 to P33 for the Semi-F Series <Complete Product> order method.