


Shaft Collar <SSC-SL2>

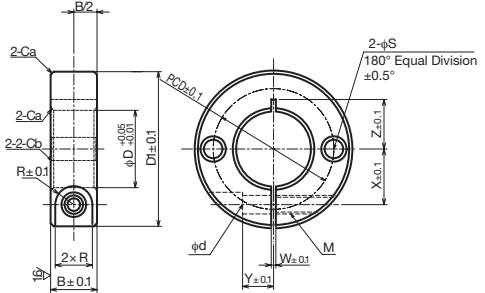

Order No. Example SSC1215SL2

Shaft Collar No.



◇ List of Shaft Collar Sizes

Shaft Collar No.	Inner Diameter ϕD	Total Width $B \pm 0.1$	Outer Diameter $D1$	Bolt Hole M	Bolt $M \times$ Length	ϕd	R	W	X
SSC 0608SL2	6	8	20	M 3	M 3x10	3.4	3	1	6
SSC 0610SL2	6	10	20	M 4	M 4x10	4.5	3.75	1	6
SSC 0808SL2	8	8	25	M 3	M 3x10	3.4	3	1.5	8
SSC 0810SL2	8	10	25	M 4	M 4x12	4.5	3.75	1.5	8
SSC 0812SL2	8	12	28	M 5	M 5x16	5.5	4.5	1.5	8.5
SSC 0815SL2	8	15	30	M 6	M 6x15	7	6	1.5	9.5
SSC 1010SL2	10	10	30	M 4	M 4x12	4.5	3.75	1.5	9
SSC 1012SL2	10	12	30	M 5	M 5x16	5.5	4.5	1.5	9
SSC 1015SL2	10	15	35	M 6	M 6x18	7	6	1.5	11
SSC 1210SL2	12	10	30	M 4	M 4x12	4.5	3.75	1.5	10
SSC 1212SL2	12	12	30	M 5	M 5x16	5.5	4.5	1.5	10
SSC 1215SL2	12	15	35	M 6	M 6x18	7	6	1.5	11
SSC 1310SL2	13	10	30	M 4	M 4x12	4.5	3.75	1.5	10
SSC 1315SL2	13	15	35	M 6	M 6x18	7	6	1.5	11
SSC 1510SL2	15	10	32	M 4	M 4x12	4.5	3.75	1.5	11
SSC 1512SL2	15	12	35	M 5	M 5x16	5.5	4.5	1.5	12
SSC 1515SL2	15	15	40	M 6	M 6x20	7	6	1.5	13
SSC 1610SL2	16	10	35	M 4	M 4x12	4.5	3.75	1.5	12
SSC 1612SL2	16	12	35	M 5	M 5x16	5.5	4.5	1.5	12
SSC 1615SL2	16	15	40	M 6	M 6x20	7	6	1.5	13
SSC 2010SL2	20	10	40	M 4	M 4x16	4.5	3.75	1.5	14
SSC 2012SL2	20	12	40	M 5	M 5x16	5.5	4.5	1.5	14
SSC 2015SL2	20	15	45	M 6	M 6x20	7	6	1.5	15
SSC 2512SL2	25	12	45	M 5	M 5x16	5.5	4.5	1.5	17
SSC 2515SL2	25	15	50	M 6	M 6x25	7	6	1.5	18
SSC 3015SL2	30	15	55	M 6	M 6x25	7	6	1.5	20
SSC 3515SL2	35	15	60	M 6	M 6x25	7	6	2	23
SSC 4018SL2	40	18	70	M 8	M 8x30	9	7	2	26
SSC 5022SL2	50	22	85	M10	M10x35	11	9	3	32