




SKINDICHT® BLK / BLK-GL

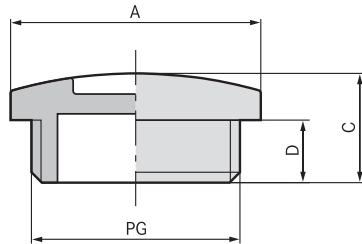

Benefits

- For closing pre-threaded holes

Application range

- Control cabinet manufacturing
- Distribution box
- Junction boxes

Product Make-up

- PG connection thread

Note

- SKINDICHT® BLK-GL offers high stability due to glass fibre reinforcement

Technical data

- Classification**
ETIM 5.0 Class-ID: EC000032
ETIM 5.0 Class-Description:
Plug for cable screw gland
- On request**
with O-ring fitted
- Colour delivered**
Light grey (RAL 7035)
- Material**
BLK: polystyrene
BLK-GL: glass fibre-reinforced polyamide
- Protection rating**
IP 54
IP 68 - 5 bar (with O-Ring)
- Temperature range**
BLK: -20°C to +70°C
BLK-GL: -40°C to +100°C

Article number	Article designation / size	Thread length, D (mm)	Pieces / PU
SKINDICHT® BLK			
52005949	BLK 7	6	100
52005950	BLK 9	6	100
52005960	BLK 11	6	100
52005970	BLK 13,5	6	100
52005980	BLK 16	6	100
52005990	BLK 21	8	50
52006000	BLK 29	8	50
52006010	BLK 36	10	25
52006020	BLK 42	10	25
52006030	BLK 48	12	25
SKINDICHT® BLK-GL			
52024848	BLK - GL 7	6	100
52024849	BLK - GL 9	6	100
52024850	BLK - GL 11	6	100
52024851	BLK - GL 13,5	6	100
52024852	BLK - GL 16	6	100
52024853	BLK - GL 21	8	50
52024854	BLK - GL 29	8	50
52024855	BLK - GL 36	10	25
52024856	BLK - GL 42	10	25
52024857	BLK - GL 48	12	25

Photographs are not to scale and do not represent detailed images of the respective products.