



丸 型

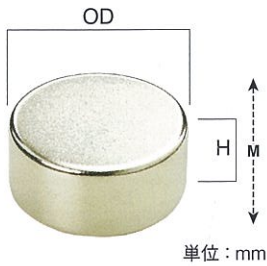

OD X H	表面磁束密度		吸着力		OD X H	表面磁束密度		吸着力	
	kG	mT	kgf	N		kG	mT	kgf	N
1) 1.2φ X 2	1.3	130	0.04	0.39	10φ X 3	3.5	350	2.0	19.61
1.5φ X 1.5	2.8	280	0.05	0.49	10φ X 4	3.8	380	2.4	23.54
2φ X 2	2.7	270	0.07	0.69	10φ X 5	4.2	420	2.6	25.50
2φ X 3	3.2	320	0.08	0.78	10φ X 10	4.8	480	3.65	35.79
3φ X 1.5	3.1	310	0.17	1.67	12φ X 1.3	2.0	200	1.45	14.22
3φ X 1.8	3.2	320	0.25	2.45	12.5φ X 1.5	2.0	200	1.8	17.65
3φ X 2	3.5	350	0.3	2.94	12.5φ X 2	2.0	200	1.9	18.63
3φ X 2.5	3.3	330	0.3	2.94	13φ X 10	4.8	480	6.1	59.82
3φ X 3	3.4	340	0.35	3.43	13φ X 20	5.5	550	9.5	93.16
3φ X 4	3.5	350	0.38	3.73	14φ X 10	4.5	450	6.4	62.76
4φ X 1.5	2.7	270	0.25	2.45	15φ X 1.5	1.8	180	1.1	10.79
4φ X 2	3.0	300	0.3	2.94	15φ X 1.7	2.0	200	1.3	12.75
4φ X 3	3.5	350	0.4	3.92	15φ X 3	3.2	320	3.7	36.28
4φ X 4	3.9	390	0.5	4.90	15φ X 4	3.3	330	4.0	39.23
4φ X 5	4.2	420	0.55	5.39	15φ X 5	3.3	330	4.5	44.13
5φ X 1	1.5	150	0.2	1.96	15φ X 10	4.2	420	6.8	66.69
2) 5φ X 1.5	2.0	200	0.3	2.94	16φ X 10	4.2	420	7.2	70.61
5φ X 2	3.2	320	0.35	3.43	17.9φ X 2.5	2.7	270	2.5	24.52
5φ X 3	3.5	350	0.44	4.31	19φ X 10	4.0	400	9.8	96.11
5φ X 4	3.8	380	0.56	5.49	20φ X 5	2.8	280	6.3	61.78
5φ X 5	4.0	400	0.65	6.37	21φ X 4.6	3.2	320	7.0	68.65
5.5φ X 1.7	2.1	210	0.3	2.94	22φ X 10	4.5	450	15.3	150.04
6φ X 2	2.2	220	0.4	3.92	23.5φ X 3.4	2.0	200	4.0	39.23
6φ X 3	2.9	290	0.6	5.88	23.5φ X 4.5	2.2	220	4.8	47.07
6φ X 5	3.5	350	0.75	7.35	23.5φ X 5	2.4	240	5.6	54.92
7φ X 2	3.0	300	0.7	6.86	24φ X 20	5.0	500	40.0	392.27
7φ X 3	3.5	350	0.77	7.55	25φ X 3.4	1.8	180	4.2	41.19
8φ X 1	1.8	180	0.5	4.90	25φ X 5	2.5	250	7.5	73.55
8φ X 2	2.2	220	0.65	6.37	25φ X 6	3.0	300	8.0	78.45
8φ X 3	3.5	350	1.1	10.79	25φ X 9.8	3.5	350	14.0	137.29
8φ X 4	3.6	360	1.25	12.26	30φ X 15	5.0	500	22.0	215.75
8φ X 5	4.0	400	1.4	13.73	32φ X 10.5	4.0	400	26.0	254.97
8φ X 8	4.2	420	1.8	17.65	40φ X 10	3.8	380	35.0	343.23
9φ X 3	3.2	320	1.2	11.77	50φ X 20	5.1	510	53.0	519.75
9.4φ X 0.8	1.5	150	0.4	3.92	100φ X 15	3.7	370	75.0	735.50
10φ X 2	2.6	260	1.3	12.75					

- 1) 金メッキ
2) 金メッキ、ニッケルメッキ
両方に対応

リング型

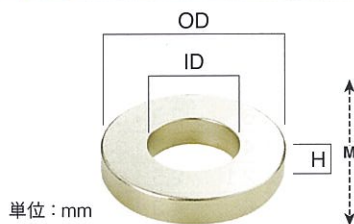

OD X ID X H	表面磁束密度		吸着力		OD X ID X H	表面磁束密度		吸着力	
	kG	mT	kgf	N		kG	mT	kgf	N
5φ X 2.4φ X 3	2.2	220	0.3	2.94	14.2φ X 10φ X 2	3.0	300	2.1	20.59
6φ X 3φ X 4	3.3	330	0.4	3.92	17φ X 8.8φ X 1.25	1.8	180	1.0	9.81
6.6φ X 2φ X 1.5	2.0	200	0.28	2.75	18φ X 7φ X 6	3.6	360	5.5	53.94
8φ X 2φ X 2.5	3.0	300	0.9	8.83	19φ X 6.5φ X 10	4.5	450	8.4	82.38
8φ X 4φ X 5	3.7	370	1.2	11.77	23φ X 8φ X 3.5	3.0	300	3.5	34.32
8.5φ X 5.5φ X 0.8	1.0	100	0.2	1.96	23φ X 8φ X 14	4.2	420	12.0	117.68
10φ X 5φ X 5	3.6	360	1.8	17.65	23φ X 13φ X 1	1.3	130	1.8	17.65
10φ X 6φ X 1	1.7	170	0.7	6.86	25φ X 7φ X 6	3.6	360	7.3	71.59
10φ X 6φ X 10	3.3	330	2.5	24.52	26φ X 20φ X 6	3.5	350	5.5	53.94
10.5φ X 7.6φ X 1	1.6	160	0.7	6.86	31.2φ X 18.2φ X 1	1.2	120	3.2	31.38
11φ X 4φ X 10	3.2	320	3.2	31.38	39φ X 19φ X 7	3.5	350	20.0	196.13
12φ X 6φ X 0.8	1.6	160	0.7	6.86	59φ X 19φ X 10	4.5	450	45.0	441.30
12φ X 7φ X 6	3.6	360	2.2	21.57	70φ X 32φ X 15	4.5	450	50.0	490.33
13.5φ X 5φ X 2	2.2	220	1.0	9.81	76φ X 42φ X 6	3.5	350	55.0	539.37
14φ X 9φ X 4	3.0	300	3.0	29.42	98φ X 58φ X 10	4.0	400	65.0	637.43

※表面磁束密度及び吸着力は参考値です