



CABLE STRIPPERS

Blades


R-TYPE

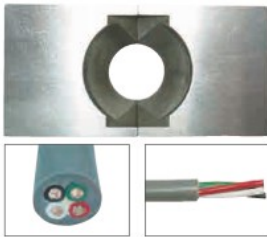


D-TYPE

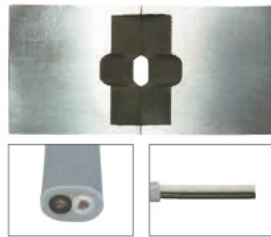

S-TYPE

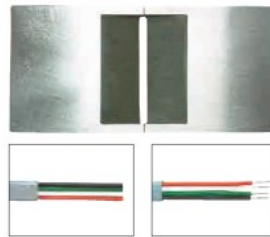

V-TYPE

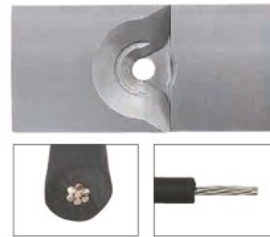

Only the CST35 has standard spare blade set

Set items

| | | |
|--------------------------|------------|------|
| Product for 1.25sq•2.0sq | RW1.25-2.0 | 1set |
| Product for 3.5sq•5.5sq | RW3.5-5.5 | 1set |
| Product for S0 | S0 | 1set |

With case



●RW1.25-2.0
for 1.25sq•2.0sq



●RW3.5-5.5
for 3.5sq•5.5sq



●S0
for S zero


※It is possible to use two sizes in one set.

※Operate the stopper bolt, please use it to adjust the blade spacing.

CST35

For thin cable

It's suitable for the high-speed stripping of the thin cable.

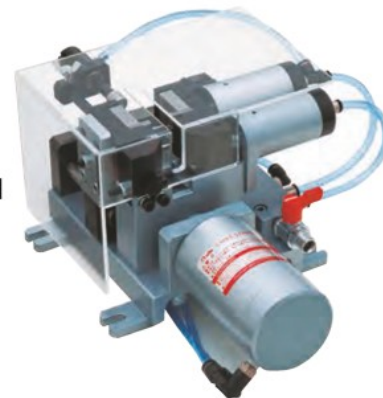


CST35 specification

| Model | Length (mm) | Weight (kg) | Height (mm) | Width (mm) | Air consumption (cm ³ /stroke) | Air pressure (MPa) | Stripping capacity ϕ (mm) | Stripping length (mm) |
|-------|-------------|-------------|-------------|------------|---|--------------------|--------------------------------|-----------------------|
| CST35 | 260 | 8 | 100 | 150 | 850 | 0.5~0.6 | up to ϕ 5mm outer dia. | 30 |

CST100

The most standard type

It can perform the complex stripping.

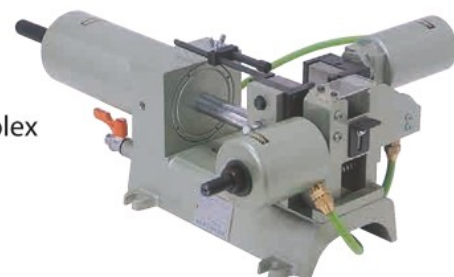

CST100 specification

| Model | Length (mm) | Weight (kg) | Height (mm) | Width (mm) | Air consumption (cm ³ /stroke) | Air pressure (MPa) | Stripping capacity ϕ (mm) | Stripping length (mm) |
|--------|-------------|-------------|-------------|------------|---|--------------------|--------------------------------|-----------------------|
| CST100 | 420 | 13.5 | 169 | 318 | 3,000 | 0.5~0.6 | up to ϕ 15mm outer dia. | 100 |