


## FCL/FCLS フランジ形たわみ軸継手

WEB 選定ナビ WEB CAD Download

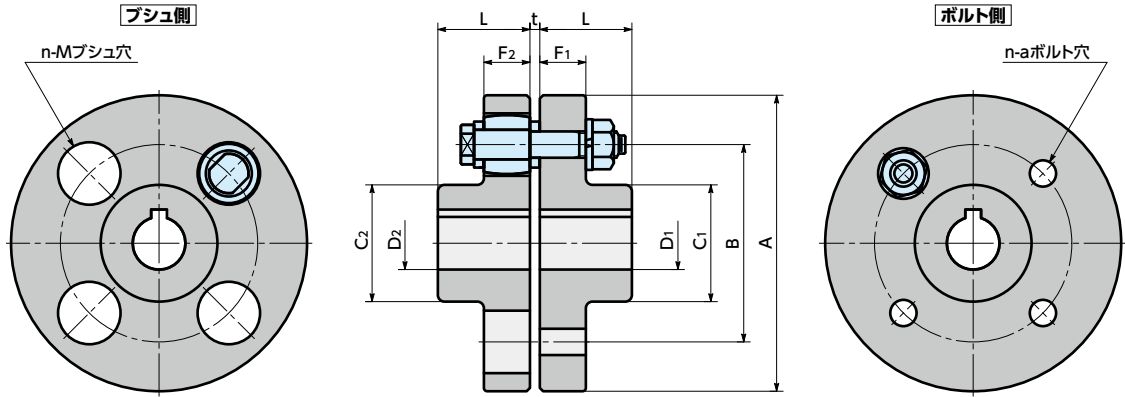

●ボルト穴の配置は、キー溝に対しておおむね振り分けです。

## 寸法・価格

単位: mm

1組品番 (部品つき)	1組価格 (円)	片側品番 (部品なし)		片側価格 (円)	A	下穴径 L	C <sub>1</sub>	C <sub>2</sub>	B	F <sub>1</sub>	F <sub>2</sub>	n (個)	a	M	t	ボルト 抜きしろ	継手ボルト 品番	
		ブッシュ側	ボルト側															
FCL-90	4,300	FCL-90-BU-FL	FCL-90-BT-FL	1,630	90	-	28	35.5	35.5	60	14	14	4	8	19	3	50	F1
FCL-100	5,220	FCL-100-BU-FL	FCL-100-BT-FL	1,950	100	-	35.5	42.5	42.5	67	16	16	4	10	23	3	56	F2
FCL-112	6,040	FCL-112-BU-FL	FCL-112-BT-FL	2,360	112	-	40	50	50	75	16	16	4	10	23	3	56	F2
FCL-125	7,380	FCL-125-BU-FL	FCL-125-BT-FL	2,790	125	-	45	56	50	85	18	18	4	14	32	3	64	F3
FCL-140	9,660	FCL-140-BU-FL	FCL-140-BT-FL	3,480	140	-	50	71	63	100	18	18	6	14	32	3	64	F3
FCL-160	13,500	FCL-160-BU-FL	FCL-160-BT-FL	4,950	160	-	56	80	80	115	18	18	8	14	32	3	64	F3
FCL-180	16,300	FCL-180-BU-FL	FCL-180-BT-FL	6,350	180	-	63	90	90	132	18	18	8	14	32	3	64	F3
FCL-200	28,200	FCL-200-BU-FL	FCL-200-BT-FL	9,820	200	18	71	100	100	145	22.4	22.4	8	20	41	4	85	F4
FCL-224	34,200	FCL-224-BU-FL	FCL-224-BT-FL	12,820	224	18	80	112	112	170	22.4	22.4	8	20	41	4	85	F4
FCL-250	49,000	FCL-250-BU-FL	FCL-250-BT-FL	18,020	250	20	90	125	125	180	28	28	8	25	51	4	100	F5
FCL-280	78,100	FCL-280-BU-FL	FCL-280-BT-FL	29,010	280	30	100	140	140	200	28	40	8	28	57	4	116	F6
FCL-315	97,900	FCL-315-BU-FL	FCL-315-BT-FL	36,400	315	30	112	160	160	236	28	40	10	28	57	4	116	F6
FCL-355	147,000	FCL-355-BU-FL	FCL-355-BT-FL	51,820	355	30	125	180	180	260	35.5	56	8	35.5	72	5	150	F7
FCL-400	198,000	FCL-400-BU-FL	FCL-400-BT-FL	71,900	400	48	125	200	200	300	35.5	56	10	35.5	72	5	150	F7
FCL-450	266,000	FCL-450-BU-FL	FCL-450-BT-FL	100,480	450	58	140	224	224	355	35.5	56	12	35.5	72	5	150	F7
FCL-560	408,000	FCL-560-BU-FL	FCL-560-BT-FL	166,060	560	78	160	250	250	450	35.5	56	14	35.5	72	5	150	F7
FCL-630	532,000	FCL-630-BU-FL	FCL-630-BT-FL	217,220	630	90	180	280	280	530	35.5	56	18	35.5	72	5	150	F7
FCL-710B	1,280,000	FCL-710B-FL	FCL-710B-FL	549,520	710	110	224	315	315	600	56	56	24	35.5	72	5	174	F7L
FCL-711B	1,560,000	FCL-711B-FL	FCL-711B-FL	626,000	710	120	250	355	355	580	80	80	20	45	87	7	240	F8
FCL-800B	2,110,000	FCL-800B-FL	FCL-800B-FL	885,600	800	130	265	375	375	670	80	80	22	45	87	7	240	F8
FCLS-112	18,400	FCLS-112-BU-FL	FCLS-112-BT-FL	8,540	112	13	40	50	50	75	16	16	4	10	23	3	56	F2
FCLS-125	19,800	FCLS-125-BU-FL	FCLS-125-BT-FL	9,000	125	13	45	56	50	85	18	18	4	14	32	3	64	F3
FCLS-140	25,100	FCLS-140-BU-FL	FCLS-140-BT-FL	11,200	140	13	50	71	63	100	18	18	6	14	32	3	64	F3
FCLS-160	33,800	FCLS-160-BU-FL	FCLS-160-BT-FL	15,100	160	14	56	80	80	115	18	18	8	14	32	3	64	F3
FCLS-180	39,000	FCLS-180-BU-FL	FCLS-180-BT-FL	17,700	180	14	63	90	90	132	18	18	8	14	32	3	64	F3
FCLS-200	58,200	FCLS-200-BU-FL	FCLS-200-BT-FL	24,820	200	18	71	100	100	145	22.4	22.4	8	20	41	4	85	F4
FCLS-224	73,000	FCLS-224-BU-FL	FCLS-224-BT-FL	32,220	224	18	80	112	112	170	22.4	22.4	8	20	41	4	85	F4
FCLS-250	104,000	FCLS-250-BU-FL	FCLS-250-BT-FL	45,520	250	20	90	125	125	180	28	28	8	25	51	4	100	F5
FCLS-280	164,000	FCLS-280-BU-FL	FCLS-280-BT-FL	71,960	280	30	100	140	140	200	28	40	8	28	57	4	116	F6
FCLS-315	226,000	FCLS-315-BU-FL	FCLS-315-BT-FL	100,450	315	32	112	160	160	236	28	40	10	28	57	4	116	F6
FCLS-355	326,000	FCLS-355-BU-FL	FCLS-355-BT-FL	141,320	355	32	125	180	180	260	35.5	56	8	35.5	72	5	150	F7
FCLS-400	425,000	FCLS-400-BU-FL	FCLS-400-BT-FL	185,400	400	50	125	200	200	300	35.5	56	10	35.5	72	5	150	F7
FCLS-450	564,000	FCLS-450-BU-FL	FCLS-450-BT-FL	249,480	450	60	140	224	224	355	35.5	56	12	35.5	72	5	150	F7
FCLS-560	936,000	FCLS-560-BU-FL	FCLS-560-BT-FL	430,060	560	80	160	250	250	450	35.5	56	14	35.5	72	5	150	F7
FCLS-630	1,370,000	FCLS-630-BU-FL	FCLS-630-BT-FL	636,220	630	90	180	280	280	530	35.5	56	18	35.5	72	5	150	F7