




SNSS-FT Socket Head Cap Screws - Full Thread

WEB Selection Tool WEB CAD Download SUS Stainless steel

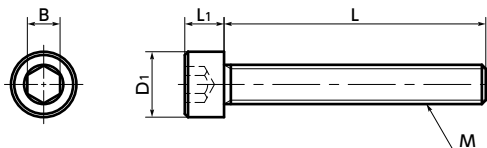

● Full thread socket head cap screws.

● Application

Equipment and devices that require long screws

● Material/Finish

RoHS Compliant

SNSS-FT	
Main Body	SUSXM7 (S.S. grade : A2)
Strength Class	A2-50

Unit : mm

Part Number	M	L																D1	L1	B	Mass (g)	
SNSS-M3-FT	M3	25	30	35	40	45	50											5.5	3	2.5	1.6 - 2.9	
SNSS-M4-FT	M4		30	35	40	45	50	55	60	65	70	75	80	85	90	100		7	4	3	3.7 - 11	
SNSS-M5-FT	M5		30	35	40	45	50	55	60	65	70	75	80	85	90	100		8.5	5	4	5.6 - 16	
SNSS-M6-FT	M6			35	40	45	50	55	60	65	70	75	80	85	90	100		10	6	5	9.9 - 24	
SNSS-M8-FT	M8				40	45	50	55	60	65	70	75	80	85	90	100		13	8	6	21 - 45	
SNSS-M10-FT	M10					45	50	55	60	65	70	75	80	85	90	100	110	120	16	10	8	36 - 84

Part Number	Qty per pack
SNSS-M3-FT	1
SNSS-M4-FT	1
SNSS-M5-FT	1
SNSS-M6-FT	1
SNSS-M8-FT	1
SNSS-M10-FT	1

● Related Products

SSH-FT Socket Head Cap Screw with Special Low Profile - Full Thread
 → P.594



SPE-FT Plastic Screw - Socket Head Cap Screws - Full Thread - PEEK
 → P.734



● Part number specification

SNSS - M3 - 25 - FT

Product Code **1** **2** Product Code

1 Individual Sales → P.794	2 Cleanroom Wash & Packaging → P.792	3 Screw Length Adjustment → P.796	4 Vibration Resistant → P.795	5 Modification process for captive use → P.791
1 unit in 1 bag	Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Not Available