




SRTS Two Hole Pan Head Machine Screws

WEB Selection Tool WEB CAD Download Tamper Resistance SUS Stainless steel

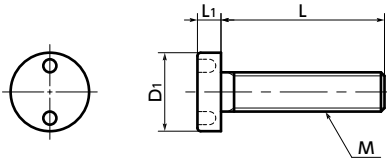

● Part number specification

SRTS-M5-16



Order in number of packs.
The minimum order quantity is 1 piece. → P.794

- They cannot be installed or removed by using standard tools.
- Install and remove by **SRTB** Specialty Bits and **SRD** Specialty Magnetic Screwdriver together.
- The simple head design is suitable for decoration.
- Application

Machinery, tools, equipment, and devices disassembly prevention - tampering prevention, theft prevention for outdoor facilities, security measures, and safety measures

● Material/Finish



	SRTS
Main Body	SUS304
Strength Class	Equivalent to A2-50

Unit : mm

Part Number	M	L			D1	L1	Bit Part No.	Screwdriver Part No.	Mass (g)
SRTS-M3	M3	6	8	10	6	1.8	SRTB-4	SRD-6.35	0.66 - 0.82
SRTS-M4	M4			10	8	2.4	SRTB-8	SRD-6.35	1.7 - 2.2
SRTS-M5	M5				10	3	SRTB-10	SRD-6.35	3.4 - 4.3


Part Number	Qty*1 per pack
SRTS-M3	20
SRTS-M4	20
SRTS-M5	20

*1 The minimum order quantity is 1 piece. → P.794

● SRTB Dedicated bit

Unit : mm


Part Number	L	B	Mass (g)	Qty per pack
SRTB-4	25.4	6.35	5	1
SRTB-8	25.4	6.35	5	1
SRTB-10	25.4	6.35	5.2	1

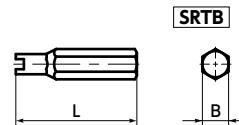

● SRD Dedicated magnet screwdriver

Unit : mm

Part Number	L	B	Mass (g)	Qty per pack
SRD-6.35	210	6.35	98	1

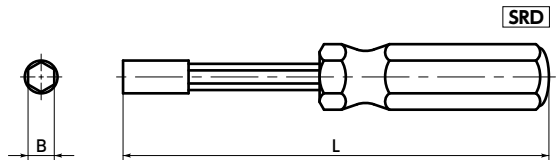

1 Individual Sales → P.794 Cleanroom Wash & Packaging → P.792 Screw Length Adjustment → P.796 Vibration Resistant → P.795 Modification process for captive use → P.791

Available / Add'l charge Available / Add'l charge Available / Add'l charge Available / Add'l charge Available / Add'l charge