



RoHS対応

ERON®


UNIVERSAL CLAMPS

PAT.P No.E-307N

## ユニバーサルクランプ

部品名	材質	熱処理	表面処理
本体	鍛造S45C	-	-
半円筒座金	S45C	焼入HRC30	-

背の高いワークから低いワークまで無段階で締付できます。

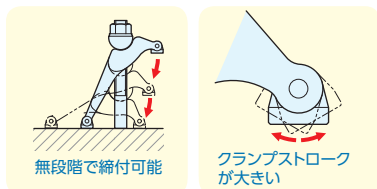

## 仕様・価格表

オーダーNo.	No.	適合T溝巾	クランピングスタッド	フランジナット	Tスロットナット	クランプ距離	クランプストローク	最大操作トルク	最大締付力 kN	質量kg	価格
03296	EUC-090PN1	14	BC12145	FNM0012	TNM1412	20-39	0- 90	55.8	8.9	0.83	6,300
03314	EUC-090PN2	16	BC12145	FNM0012	TNM1612	20-39	0- 90	55.8	8.9	0.84	6,400
03315	EUC-090PN3	12	BC10145	FNM0010	TNM1210	20-39	0- 90	32.4	6.1	0.77	6,400
03316	EUC-090PN4	14	BC10145	FNM0010	TNM1410	20-39	0- 90	32.4	6.1	0.80	6,400
03297	EUC-100PN1	18	BC16175	FNM0016	TNM1816	25-48.5	0-100	136	17.4	1.44	10,500
03317	EUC-100PN2	20	BC16175	FNM0016	TNM2016	25-48.5	0-100	136	17.4	1.46	10,600
03318	EUC-100PN3	18	BC14175	FNM0014	TNM1814	25-48.5	0-100	85.8	12.5	1.37	10,600
03319	EUC-100PN4	16	BC14175	FNM0014	TNM1614	25-48.5	0-100	85.8	12.5	1.34	10,600
03298	EUC-120PN1	22	BC20200	FNM0020	TNM2220	34-56	0-100	265	25.3	2.59	16,400
03320	EUC-120PN2	24	BC20200	FNM0020	TNM2420	34-56	0-100	265	25.3	2.62	16,800
03321	EUC-120PN3	26	BC20200	FNM0020	TNM2620	34-56	0-100	265	25.3	2.69	16,800
03322	EUC-120PN4	20	BC18200	FNM0018	TNM2018	34-57	0-105	145	19.3	2.41	16,800
03328	EUC-120PN5	22	BC18200	FNM0018	TNM2218	34-57	0-105	145	19.3	2.49	16,800
03329	EUC-120PN6	24	BC18200	FNM0018	TNM2418	34-57	0-105	145	19.3	2.52	16,800
04864	EUC-120PN7	18	BC16200	FNM0016	TNM1816	34-58.5	0-115	136	18.1	2.33	16,800
04865	EUC-120PN8	16	BC14200	FNM0014	TNM1614	34-59.5	0-125	85.8	11.3	2.22	16,800
03299	EUC-150PN1	28	BC24250	FNM0024	TNM2824	42-71.5	0-125	458	26.4	4.83	22,000
03323	EUC-150PN2	32	BC24250	FNM0024	TNM3224	42-71.5	0-125	458	26.4	4.96	24,900
03324	EUC-150PN3	28	BC22250	FNM0022	TNM2822	42-72	0-130	280	24.5	4.68	22,500
03325	EUC-150PN4	26	BC22250	FNM0022	TNM2622	42-74	0-140	280	24.5	4.59	22,500
04868	EUC-150PN5	24	BC20250	FNM0020	TNM2420	42-74	0-140	265	30.6	4.42	22,500
04869	EUC-150PN6	22	BC20250	FNM0020	TNM2220	42-75	0-145	265	30.6	4.39	22,500
04866	EUC-150PN7	20	BC18250	FNM0018	TNM2018	72-75.5	0-150	145	15.6	4.18	22,500
04867	EUC-150PN8	18	BC16250	FNM0016	TNM1816	72-76	0-155	136	18.2	4.09	22,500

※最大締付力はクランプストローク(A寸法)の最大のとき

## 部品価格

## 本体

適合機種	オーダーNo.	No.	クランプストローク	価格
EUC-090PN(1-4)	10008	EUC090-BD	90	4,330
EUC-100PN(1-4)	10009	EUC100-BD	100	7,800
EUC-120PN(1-8)	10010	EUC120-BD	120	13,300
EUC-150PN(1-8)	10011	EUC150-BD	150	17,800

## 参照ページ

E-400C クランピングスタッド  P.504 ▶	E-402 Tスロットナット  P.468 ▶	E-403 フランジナット  P.458 ▶
--	---	--

## 半円筒座金

適合機種	オーダーNo.	No.	価格
EUC-090PN1,2	10012	EUC090-WH12	780
EUC-090PN3,4	10013	EUC090-WH10	780
EUC-100PN1,2	10014	EUC100-WH16	1,080
EUC-100PN3,4	10015	EUC100-WH14	1,080
EUC-120PN1,2,3	10018	EUC120-WH20	1,560
EUC-120PN4,5,6	10019	EUC120-WH18	1,560
EUC-120PN7	10020	EUC120-WH16	1,560
EUC-120PN8	10021	EUC120-WH14	1,560
EUC-150PN1,2	10022	EUC150-WH24	2,380
EUC-150PN3,4	10023	EUC150-WH22	2,380
EUC-150PN5,6	10024	EUC150-WH20	2,380
EUC-150PN7	10025	EUC150-WH18	2,380
EUC-150PN8	10026	EUC150-WH16	2,380