
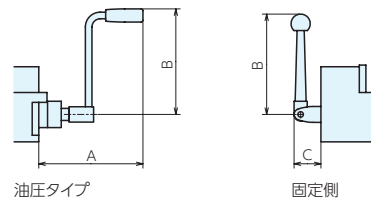
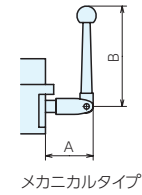


ハンドル

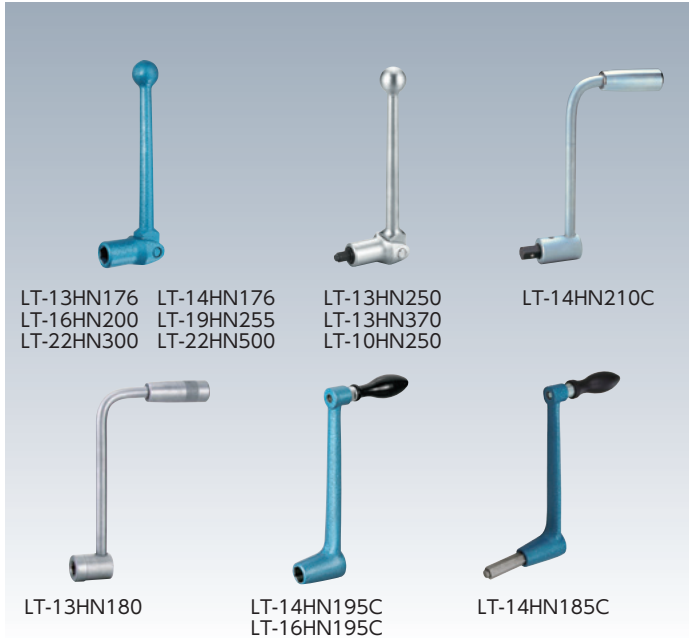

仕様・価格表

適合機種	A	B	C	差込六角対辺	オーダーNo.	No.	価格
LT-HPD150	111.5	168	-	13	43944	LT-13HN176	4,020
LTM100WL,LTAW100	103	168	-	14	43945	LT-14HN176	4,020
LT100M,LT100SP	44	168	-	14			
LTFV75	64	168	-	14			
LT100MC	70.5	168	-	14			
LTCV100(S),LTCV125(S)	87	189	49	16	43946	LT-16HN200	4,260
LT125M	58	189	-	16			
LT125SP	58	189	-	16			
LTCV160(S),LTCV200(S)	98	246	60	19	43947	LT-19HN255	4,520
LT150M	67	246	-	19			
LT150L	81	246	-	19			
LT150MC	97	246	-	19			
LTM150WL	151.5	246	-	19			
LT200M	76.5	277	-	22	43948	LT-22HN300	5,300
LT250M	91.5	504	-	22	43949	LT-22HN500	8,000
LT630JV	146・296	197.5	-	14	43950	LT-14HN195C	4,260
LTH3P-125	177~402	197.5	-	16	43952	LT-16HN195C	4,260
LTH3P-150S	129~429	197.5	-	14	69397	LT-14HN185C	4,520
LTCV100(S)H,LTCV125(S)H,LTCV160(S)H,LTCV200(S)H	190	192.5	-	14	43951	LT-14HN210C	7,100
LTCV-160TH,LTCV-200TH	208.5	192.5	-	14			
LTFH150Q,LTFH175Q,LTFV150Q,LTFV175Q	231.5	192	-	13	62539	LT-13HN180	7,100
LTFH125Q,LTFV125Q	209.5	192	-	13			
LTFV100Q	189.5	192	-	13			
LT5AU100(F,M,FM)	78	245.5	-	13	88805	LT-13HN250	8,800
LT5AU100(F,M,FM)	77	368.5	-	13	88806	LT-13HN370	9,800
LT5AU-75(F,FM)	78	245.5	-	10	96856	LT-10HN250	8,800

ベースエレメント

クランプユニット

ローケーティング
エレメントクランプピン
パーツ

補助ベース

マシンバイス

ボール盤バイス

技術資料

索引