

RoHS対応

ERON®


FLAT BASE PLATES

No.E-604

フラットベースプレート

材質 FC250


熱処理 焼純

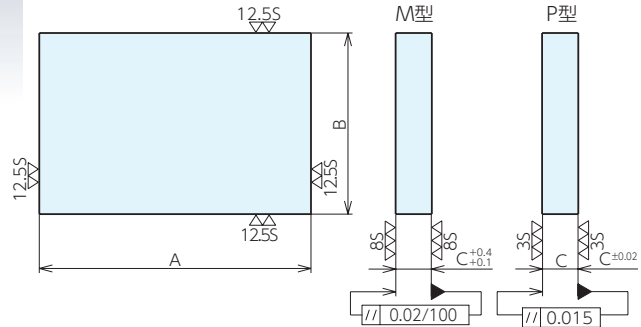

仕様・価格表


No.	A	B	C	質量kg	機械仕上M型			研削仕上P型		
					オーダーNo.	No.	価格	オーダーNo.	No.	価格
604-301	300	80	20	3.6	04573	604-301M	13,900	04836	604-301P	15,300
604-302	300	100	20	4.5	04574	604-302M	15,400	04837	604-302P	17,500
604-303	300	160	20	6.9	04575	604-303M	21,000	04838	604-303P	22,900
604-304	300	200	20	8.7	04576	604-304M	24,000	04839	604-304P	26,800
604-305	300	250	20	10.8	04577	604-305M	27,200	04840	604-305P	30,500
604-306	300	125	25	6.9	04578	604-306M	18,800	04841	604-306P	20,700
604-307	300	200	25	10.8	04579	604-307M	25,800	04842	604-307P	28,800
604-308	300	250	25	13.5	04580	604-308M	42,800	04843	604-308P	45,800
604-309	300	315	25	17.1	04581	604-309M	53,000	04844	604-309P	56,000
604-310	300	160	32	11.1	04582	604-310M	34,800	04845	604-310P	37,000
604-311	300	250	32	17.4	04583	604-311M	48,200	04846	604-311P	51,000
604-312	300	315	32	21.9	04584	604-312M	60,000	04847	604-312P	63,500
604-313	300	400	32	27.9	04585	604-313M	75,000	04848	604-313P	77,000
604-314	300	200	40	17.4	04586	604-314M	45,800	04849	604-314P	48,600
604-315	300	250	40	21.6	04587	604-315M	55,000	04850	604-315P	58,000
604-316	300	315	40	27.3	04588	604-316M	68,500	04851	604-316P	71,000
604-317	300	400	40	34.5	04589	604-317M	85,500	04852	604-317P	87,500
604-318	300	315	50	34.5	04590	604-318M	78,000	04853	604-318P	81,500
604-319	300	500	50	54.8	04591	604-319M	120,000	04854	604-319P	125,000
604-601	600	125	25	13.8	04955	604-601M	45,200	04592	604-601P	49,700
604-602	600	200	25	21.6	04956	604-602M	62,000	04593	604-602P	69,000
604-603	600	250	25	27.0	04957	604-603M	103,000	04594	604-603P	110,000
604-604	600	315	25	34.2	04958	604-604M	128,000	04595	604-604P	135,000
604-605	600	160	32	22.2	04959	604-605M	83,000	04596	604-605P	88,000
604-606	600	250	32	34.8	04960	604-606M	116,000	04597	604-606P	123,000
604-607	600	315	32	43.8	04961	604-607M	145,000	04598	604-607P	152,000
604-608	600	400	32	55.8	04962	604-608M	180,000	04599	604-608P	187,000
604-609	600	200	40	34.8	04963	604-609M	110,000	04600	604-609P	117,000
604-610	600	250	40	43.2	04964	604-610M	131,000	04601	604-610P	139,000
604-611	600	315	40	54.6	04965	604-611M	164,000	04602	604-611P	170,000
604-612	600	400	40	69.0	04966	604-612M	205,000	04603	604-612P	212,000
604-613	600	315	50	67.8	04967	604-613M	188,000	04604	604-613P	195,000
604-614	600	500	50	108.0	04968	604-614M	290,000	04605	604-614P	300,000

使用例

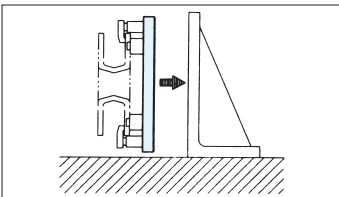

参照ページ

フリーSSプレート

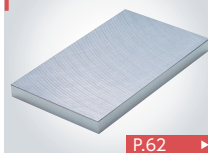

P.62 ▶

フリーALプレート



P.64 ▶

補助ベース

組込用部品

ジャッキ

除振・防振

技術資料

索引