


# PPS/BT

ポリフェニレンサルファイド／六角ボルト  
Polyphenylene sulfide / Hexagon head bolt

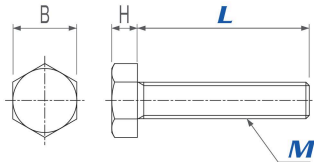


品番 Product number		PPS/BT-M○-L○						
M	M4	M5	M6	M8	M10	M12		
ピッチ / Pitch	0.7	0.8	1	1.25	1.5	1.75		
B × H	7×2.8	8×3.5	10×4	13×5.5	17×7	19×8		
L	8	100	100	—	—	—		
	10	100	100	100	50	—		
	12	100	100	100	50	—		
	15	100	100	100	50	—		
	20	100	100	100	50	50	50	
	25	100	100	100	50	50	50	
	30	—	100	100	50	50	50	
	35	—	100	—	—	—	—	
	40	—	—	100	50	50	50	
	50	—	—	—	50	50	50	

表中のカラー部分は半ネジとなります。M8-50(S=30) M10-50(S=25)  
Colored portion in the table indicates partially threaded screw.

販売単位 Quantity

# PPS/CB

ポリフェニレンサルファイド／六角穴付ボルト  
Polyphenylene sulfide / Hexagon socket head cap bolt

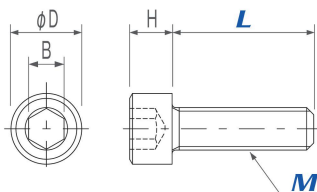


品番 Product number		PPS/CB-M○-L○						
M	M3	M4	M5	M6	M8	M10	M12	
ピッチ / Pitch	0.5	0.7	0.8	1	1.25	1.5	1.75	
D × H	5.5×3	7×4	8.5×5	10×6	13×8	16×10	18×12	
B	2.5	3	4	5	6	8	10	
L	6	100	100	—	—	—	—	
	8	100	100	100	—	—	—	
	10	100	100	100	100	100	—	
	12	100	100	100	100	100	—	
	15	100	100	100	100	100	50	
	20	100	100	100	100	100	50	50
	25	—	—	100	100	100	50	50
	30	—	—	100	100	100	50	50
	35	—	—	100	—	—	50	50
	40	—	—	—	100	100	50	50

販売単位 Quantity

# PPS/NT


ポリフェニレンサルファイド／六角ナット  
Polyphenylene sulfide / Hexagon nut

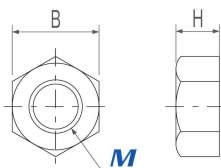

品番 Product number		PPS/NT-M○							
M	M2	M2.6	M3	M4	M5	M6	M8	M10	M12
ピッチ / Pitch	0.4	0.45	0.5	0.7	0.8	1	1.25	1.5	1.75
B × H	4×1.6	5×2	5.5×2.4	7×3.2	8×4	10×5	13×6.5	17×8	19×10
販売単位 Quantity	100	100	100	100	100	100	100	100	100

# PPS/W

ポリフェニレンサルファイド／ワッシャー  
Polyphenylene sulfide / Washer

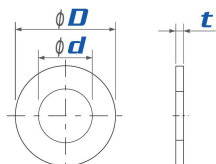

品番 Product number		PPS/W-φ <sub>d</sub> -φ <sub>D</sub> -t						
呼び径 / Nomin diameter	3	4	5	6	8	10	12	
d × D	3.2×7	4.3×9	5.3×10	6.4×12.5	8.4×17	10.5×21	13×24	
t	0.5	0.8	1	1.6	1.6	2	2.5	
販売単位 Quantity	100	100	100	100	100	100	100	

NEW  
PC  
PPS  
RENY  
PEEK  
PVC  
PI  
PP  
PTFE  
PFA  
PVDF  
CERAMIC  
ワッシャー  
ローレット  
特殊ボルト&  
特殊ナット  
スペーサー  
ワッシャー  
ワッシャー  
結束バンド  
C型止輪  
アラバネ  
オゾンガス