


N-040222 ウレタンCM



管径称	(A)	t×B	ネジ径d	T20	T25	T30	T40	T50
				P	P	P	P	P
8A	9.53	1.6×25	W3/8	55	65	75	95	115
10A	12.7	1.6×25	W3/8	58	68	78	98	118
15A	15.88	1.6×25	W3/8	61	71	81	101	121
19A	19.05	1.6×25	W3/8	64	74	84	104	124
20A	22.22	1.6×25	W3/8	67	77	87	107	127
	25.4	1.6×25	W3/8	71	81	91	111	131
25A	28.58	1.6×25	W3/8	74	84	94	114	134
	31.8	1.6×25	W3/8	77	87	97	117	137
32A	34.92	1.6×25	W3/8	80	90	100	120	140
	38.1	1.6×25	W3/8	83	93	103	123	143
40A	41.28	1.6×25	W3/8	86	96	106	126	146
	50.8	1.6×25	W3/8	96	106	116	136	156
50A	53.98	1.6×25	W3/8	99	109	119	139	159
	63.5	2.3×25	W3/8	110	120	130	150	170
65A	66.68	2.3×25	W3/8	113	123	133	153	173
80A	79.38	2.3×25	W3/8	126	136	146	166	186
100A	104.78	2.3×25	W3/8	151	161	171	191	211

単位(m/m)

- 銅管用置き配管用ウレタン一式です。
- 銅管用ウレタンは溝のないタイプです。

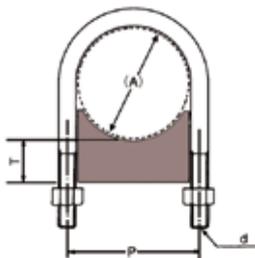


N-040209 ウレタンEP



管径称	(A)	ネジ径d	T20	T25	T30	T40	T50
			P	P	P	P	P
15A	21.7	W5/16	31	31	31		
20A	27.2	W5/16	37	37	37	37	37
25A	34.0	W5/16	44	44	44	44	44
32A	42.7	W3/8	52	52	52	52	52
40A	48.6	W3/8	62	62	62	62	62
50A	60.5	W3/8	74	74	74	74	74
65A	76.3	W3/8	88	88	88	88	88
80A	89.1	W3/8	101	101	101	101	101
100A	114.3	W3/8		126	126	126	126
125A	139.8	W1/2		154	154	154	154
150A	165.2	W1/2		182	182	182	182
200A	216.3	W1/2			232	232	232
250A	267.4	W5/8			286	286	286
300A	318.5	W5/8				341	341

単位(m/m)

- 高さ調整用ウレタン一式です。
- T20・T25・T30は足長Uボルト(30長)を使用します。
- T40・T50は足長Uボルト(50長)を使用します。

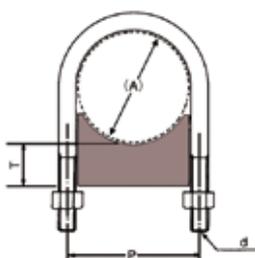

N-040219 ステンウレタンEP



管径称	(A)	ネジ径 d	T20	T25	T30	T40	T50
			P	P	P	P	P
15A	21.7	W3/8	34	34	34		
20A	27.2	W3/8	40	40	40	40	40
25A	34.0	W3/8	46	46	46	46	46
32A	42.7	W3/8	56	56	56	56	56
40A	48.6	W3/8	62	62	62	62	62
50A	60.5	W3/8	74	74	74	74	74
65A	76.3	W3/8	88	88	88	88	88
80A	89.1	W3/8	101	101	101	101	101
100A	114.3	W3/8		126	126	126	126
125A	139.8	W1/2		154	154	154	154
150A	165.2	W1/2		182	182	182	182

単位(m/m)

- ステン足長Uボルト付きウレタンEPタイプです。
- T20・T25・T30は足長Uボルト(30長)を使用します。
- T40・T50は足長Uボルト(50長)を使用します。
- Uボルト材質:SUS304

納期をご確認下さい。 電気亜鉛めっき