


# NK-6800 Double Bellows Type

This product has 2 bellows, so it can move very well.  
Flange Standard: JIS,ANSI,DIN

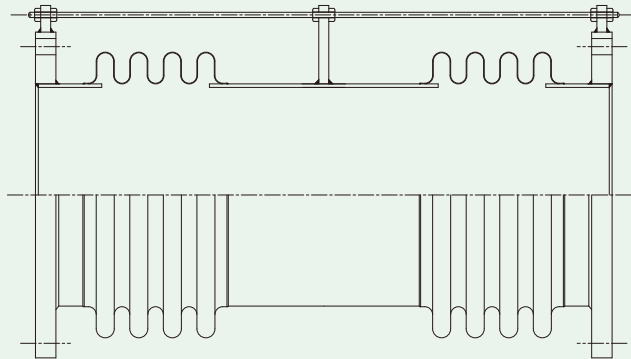

DN	Length(mm)					
	Y=50	Y=100	Y=150	Y=200	Y=250	Y=300
50mm	600	800	950	1100	1300	1500
65mm	600	750	850	1000	1100	1250
80mm	700	800	950	1100	1200	1300
100mm	600	800	1000	1150	1250	1350
125mm	650	850	950	1100	1250	1400
150mm	700	850	1050	1200	1350	1500
200mm	800	1000	1200	1350	1500	1700
250mm	800	1100	1350	1550	1700	1900
300mm	850	1150	1400	1700	1900	2100
350mm	850	1150	1400	1700	1900	2100
400mm	900	1200	1500	1750	1950	2200
450mm	950	1250	1550	1800	2050	2300
500mm	900	1200	1400	1650	1850	2000
550mm	950	1250	1500	1700	1900	2100
600mm	1000	1300	1550	1800	1950	2200

① Bellows	Stainless Steel
② End Pipe	Carbon Steel, Stainless Steel
③ Flange	Carbon Steel, Stainless Steel
④ Holder	Carbon Steel, Stainless Steel
⑤ Set Bolt	Carbon Steel, Stainless Steel
⑥ Common Connector	Carbon Steel, Stainless Steel