

MRBLN230-6


Size R0.15 ~ R1



MUGEN COATING 2-Flute Long Neck Ball End Mill (Shank Dia. 6)

Total 10 sizes

2-flute long neck ball end mill. Shank Dia.6mm

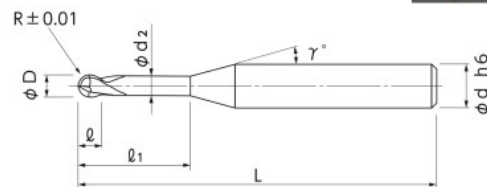

Regular Line
MUGEN COATING
Long Neck Type

Carbon Steel **P**

Alloy Steel **P**

Prehardened Steel **P**

Hardened Steel ~55 HRC **H**

Stainless Steel **M**

Aluminium Alloy **N**

Copper **N**

Resin **O**

Unit : mm

Code No.	Radius (R)	Under Neck Length (ℓ ₁)	Length of Cut (ℓ)	Dia. (D)	Neck Dia. (d ₂)	Neck Taper Angle (γ)	Shank Dia. (d)	Overall Length (L)
08-00522-01501	R0.15	3	0.3	0.3	0.28	15°	6	60
08-00522-02001	R0.2	4	0.4	0.4	0.37	15°	6	60
08-00522-02501	R0.25	5	0.8	0.5	0.46	15°	6	60
08-00522-03001	R0.3	3	1	0.6	0.56	15°	6	60
08-00522-03005		5	1	0.6	0.56	15°	6	60
08-00522-03006		6	1	0.6	0.56	15°	6	60
08-00522-04008	R0.4	8	1.4	0.8	0.76	15°	6	60
08-00522-05010	R0.5	10	1.5	1	0.95	15°	6	60
08-00522-07515	R0.75	15	1.75	1.5	1.45	15°	6	60
08-00522-10020	R1	20	2	2	1.94	15°	6	60

How to Order

When you order, indicate MRBLN230-6 (R)×(ℓ₁). ※(γ) is reference value.

■ Semi-standard products, please inquire for price and delivery.

