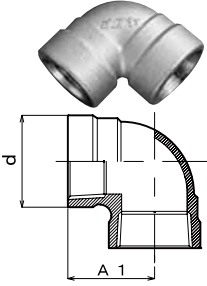
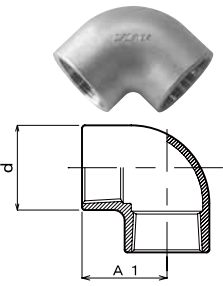
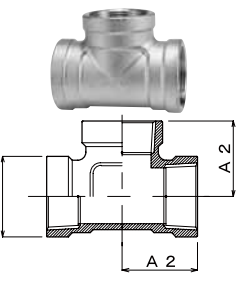
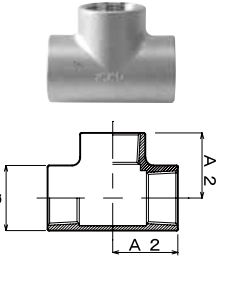
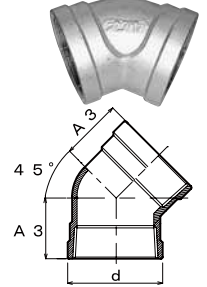
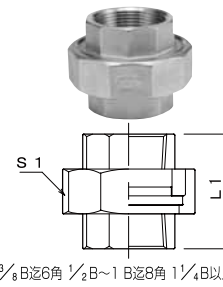
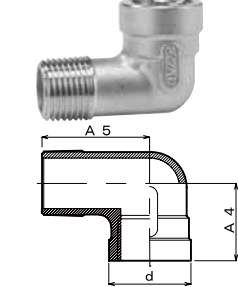
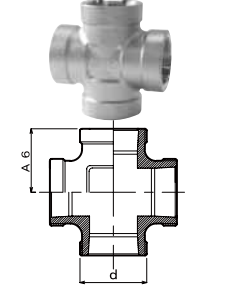


ステンレス製ねじ込み管継手

MADE OF STAINLESS STEEL

SCS13A (SUS304)

品名	90°エルボ	バンド無エルボ	チー	バンド無チー
記号	L	LX	T	TX
形状				
呼び径 (B)	A1	A1	A2	A2
1/8	17	17	17	17
1/4	19	19	19	19
3/8	23	23	23	23
1/2	27	27	27	27
3/4	32	32	32	32
1	38	38	38	38
1 1/4	45	45	45	45
1 1/2	48	48	48	48
2	57	57	57	57
2 1/2	69		69	
3	78		78	
4	97		97	

品名	45°エルボ	ユニオン	ストリートエルボ	クロス
記号	45L	U	SL	X
形状				
呼び径 (B)	A3	L1	A4	A6
1/8	16	30.5	17	18
1/4	17	35	19	19
3/8	19	37	23	23
1/2	21	39.5	27	27
3/4	25	42.5	32	33
1	29	51	38	38
1 1/4	33	55	46	46
1 1/2	37	58	48	48
2	42	65.5	57	57
2 1/2	49	78	69	69
3	54	87.5	78	78
4	65			97

単位：mm



NAGOYA Co.,LTD