




溝付きピン B形 DIN 1472

材質 快削鋼

表面処理 呼び径4以上は黒染

仕様・規格・サイズ表

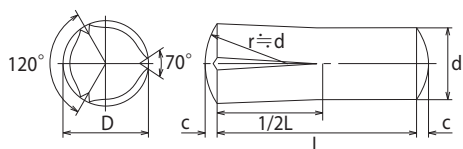

呼び寸法 dXL

d	C	L												
		D												
1.5	h9	0.2	6	8	10	12	16	20						
			1.63	1.63	1.63	1.63	1.63	1.63						
2	h9	0.25	6	8	10	12	16	20	26	30				
			2.15	2.15	2.15	2.15	2.15	2.15	2.15	2.15	2.15			
2.5	h9	0.3	6	8	10	12	16	20	26	30				
			2.65	2.65	2.65	2.7	2.7	2.7	2.7	2.7				
3	h9	0.4	6	8	10	12	16	20	26	30	40			
			3.2	3.2	3.2	3.25	3.25	3.3	3.3	3.3	3.3	3.25		
4	h11	0.5	10	12	16	20	26	30	36	40	45			
			4.25	4.25	4.3	4.3	4.35	4.35	4.35	4.35	4.3			
5	h11	0.6	10	12	14	16	20	26	30	36	40	45		
			5.25	5.25	5.25	5.3	5.3	5.35	5.35	5.35	5.35	5.35	5.35	
6	h11	0.8	10	12	16	20	26	30	36	40	45	50	55	60
			6.25	6.25	6.25	6.3	6.3	6.3	6.35	6.35	6.35	6.35	6.35	6.35
8	h11	1.0	16	20	26	30	36	40	45	50	55	60		
			8.25	8.3	8.35	8.35	8.35	8.4	8.4	8.4	8.4	8.4		
10	h11	1.2	30	70										
			10.4	10.45										