

Reamers

Endmills

Drills

Countersinks/
Counterbores

Slitting Saws/
Cut-off tools

Cutters

Side
Milling

Staggered


Angle

Plain

for Pipe

PC

ブレンカッター
Plain Milling Cutters

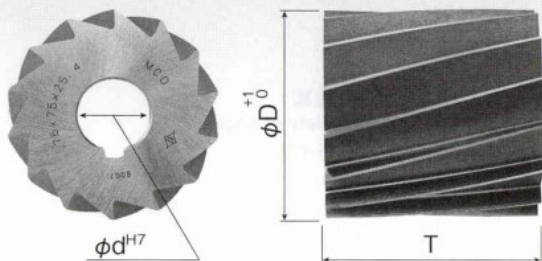

厚み(T)の寸法許容差
Tolerance of thickness(T)

厚み(T) Thickness(T)	許容差 Tolerance
30	±0.30
40	±0.40
50	±0.50
60	±0.60
70	±0.70
80	±0.80
100	±1.00
125	±1.25
150	±1.50

- 外径、厚みが豊富
Wide variety of diameters and thicknesses
- MCO材(コバルト高速度鋼)を使用
Uses MCO material (Cobalt high-speed steel)

※左ネジレ15° Left helix 15°

穴径φ25.4 Hole Dia.φ25.4

品番 Product No.	寸法 Size				標準価格 Standard price ¥
	刃径 D	厚み T	穴径 d	刃数 NT	
PCT050X030	50	30	25.4	12	22,200
PCT050X040	50	40	25.4	12	28,400
PCT050X050	50	50	25.4	12	34,500
PCT050X060	50	60	25.4	12	43,300
PCT050X070	50	70	25.4	12	56,900
PCT050X080	50	80	25.4	12	72,200
PCT050X100	50	100	25.4	12	82,200
PCT060X030	60	30	25.4	14	30,600
PCT060X040	60	40	25.4	14	40,400
PCT060X050	60	50	25.4	14	48,800
PCT060X060	60	60	25.4	14	58,000
PCT060X070	60	70	25.4	14	72,500
PCT060X080	60	80	25.4	14	87,500
PCT060X100	60	100	25.4	14	104,300
PCT075X030	75	30	25.4	14	43,600
PCT075X040	75	40	25.4	14	64,700
PCT075X050	75	50	25.4	14	72,900
PCT075X060	75	60	25.4	14	85,600
PCT075X070	75	70	25.4	14	98,500
PCT075X080	75	80	25.4	14	107,700
PCT075X100	75	100	25.4	14	137,100
PCT075X125	75	125	25.4	14	172,500
PCT075X150	75	150	25.4	14	217,000

品番 Product No.	寸法 Size				標準価格 Standard price ¥
	刃径 D	厚み T	穴径 d	刃数 NT	
PCT100X030	100	30	25.4	16	87,400
PCT100X040	100	40	25.4	16	92,400
PCT100X050	100	50	25.4	16	134,900
PCT100X060	100	60	25.4	16	152,800
PCT100X070	100	70	25.4	16	170,000
PCT100X080	100	80	25.4	16	215,100
PCT100X090	100	90	25.4	16	222,200
PCT100X100	100	100	25.4	16	235,100
PCT100X125	100	125	25.4	16	287,600
PCT100X150	100	150	25.4	16	359,200
PCT125X050	125	50	25.4	18	156,600
PCT125X100	125	100	25.4	18	297,500
PCT125X125	125	125	25.4	18	354,000
PCT125X150	125	150	25.4	18	462,200
PCT150X050	150	50	25.4	20	225,000
PCT150X100	150	100	25.4	20	461,100
PCT150X125	150	125	25.4	20	571,800
PCT150X150	150	150	25.4	20	679,600