


3Kクランプ/2Kクランプ/2Dクランプ
Clamp Type 3K/Clamp Type 2K/Clamp Type 2D

3K クランプ

Clamp Type 3K

Type CP3K

※1.0^S~1.5^S 共用

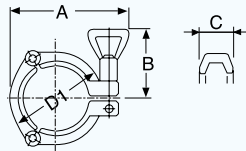


Nom.size	D1	A	B	C	Mass kg
※1.5 ^S	65.5	87.3	60	18	0.28
2.0 ^S	79	102	60	18	0.33
2.5 ^S	92.5	115.8	60	18	0.4
3.0 ^S	106	130.5	60	18	0.44
3.5 ^S	121	146	60	18	0.52
4.0 ^S	134	159.5	60	18	0.57
4.5 ^S	145	171	60	18	0.61
5.5 ^S	173	198	65	26	1
6.5 ^S	201	226	65	26	1.2
200A	251.5	277.3	65	26	1.6

2K クランプ

Clamp Type 2K

Type CP2K

※8A~15A 共用 ※1.0^S~1.5^S 共用

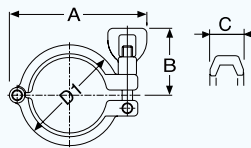



Nom.size	D1	A	B	C	Mass kg
※1.5 ^S	64	92	47	16	0.23
2.0 ^S	77.5	105	51.5	16	0.22
2.5 ^S	91	119.5	51.5	16	0.25
3.0 ^S	105	134	51.5	16	0.29
3.5 ^S	120.5	149.5	52.5	17	0.383
4.0 ^S	133.5	163	52.5	17	0.417
※15A	46	71.5	45	16	0.16

2D クランプ

Clamp Type 2D

Type CP2D

※8A~15A 共用 ※1.0^S~1.5^S 共用

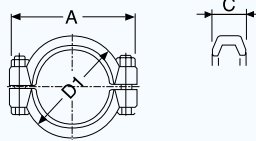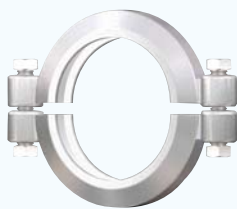

Nom.size	D1	A	C	Mass kg
※1.5 ^S	63	86	16	0.22
2.0 ^S	76.5	100	16	0.25
2.5 ^S	90	115	16	0.29
3.0 ^S	103.5	130	16	0.33
3.5 ^S	119	144	17	0.4
4.0 ^S	132	158	17	0.46
4.5 ^S	143	170	17	0.49
5.5 ^S	174	200	26	1.2
6.5 ^S	202	228	26	1.3
200A	253	278	26	1.6
※15A	46	64	16	0.13