


OZ-D メスネジ型カップラー

COUPLER FEMALE THREAD

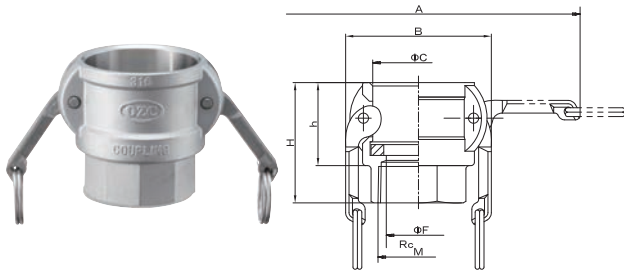


呼び径	mm	15	20	25	32	40	50	65	80	100	125	150
	inch	1/2	3/4	1	1 1/4	1 1/2	2	2 1/2	3	4		6
M		1/2B	3/4B	1B	1 1/4B	1 1/2B	2B	2 1/2B	3B	4B		6B
A		115	115	137	183	191	201	213	267	296		454
B		53	53	61	77	84	94	108	132	164		238
ΦC		32	32	37	46	54	64	76	92	120		177
ΦF		16	21	26	33	38	50	60	75	94		143
h		32	32	39	46	47	52	58	59	61		68
H		51	51	60	66	69	78	84	87	95		111

単位:mm

OZ-B オスネジ型カップラー

COUPLER MALE THREAD

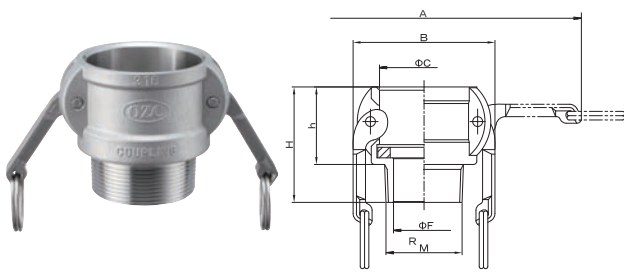


呼び径	mm	15	20	25	32	40	50	65	80	100
	inch	1/2	3/4	1	1 1/4	1 1/2	2	2 1/2	3	4
M		1/2B	3/4B	1B	1 1/4B	1 1/2B	2B	2 1/2B	3B	4B
A		115	115	137	183	191	201	213	267	296
B		53	53	61	77	84	94	108	132	164
ΦC		32	32	37	46	54	64	76	92	120
ΦF		14	19	25	31	37	50	60	75	94
h1		32	32	39	46	47	52	58	59	61
H		52	51	61	70	70	78	88	91	97

単位:mm

OZ-C ホースシャंकカップラー

COUPLER HOSE SHANK

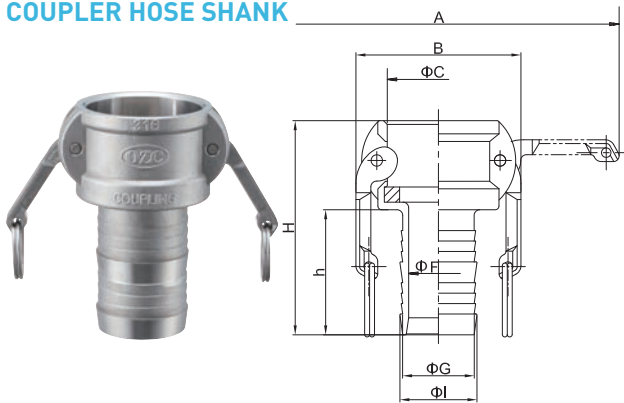

呼び径	mm	20	25	32	40	50	65	80	100	125	150	200
	inch	3/4	1	1 1/4	1 1/2	2	2 1/2	3	4		6	
A		115	137	183	191	201	213	267	296		454	
B		53	61	77	84	94	108	132	164		238	
ΦC		32	37	46	54	64	76	92	120		177	
ΦF		13	19	26	31	44	56	68	92		140	
ΦG		19	25	32	38	50	63	75	101		152	
ΦI		21	27	34	41	53	67	79	105		155	
h		51	60	63	66	77	86	102	110		144	
H		83	99	109	113	129	142	161	171		214	

単位:mm