


OZ-D メスネジ型カップラー

COUPLER FEMALE THREAD

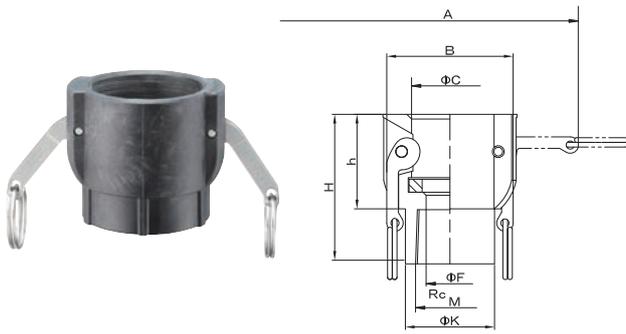


呼び径	mm	20	25	32	40	50	80
	inch	3/4	1	1 1/4	1 1/2	2	3
M		3/4B	1B	1 1/4B	1 1/2B	2B	3B
A		93	125	175	188	198	249
B		64	65	82	89	99	135
ΦC		33	37	46	54	64	93
ΦF		20	23	32	37	51	78
K		36	43	52	62	75	101
h		34	46	50	52	57	60
h		54	73	72	73	80	91

単位:mm

OZ-B オスネジ型カップラー

COUPLER MALE THREAD

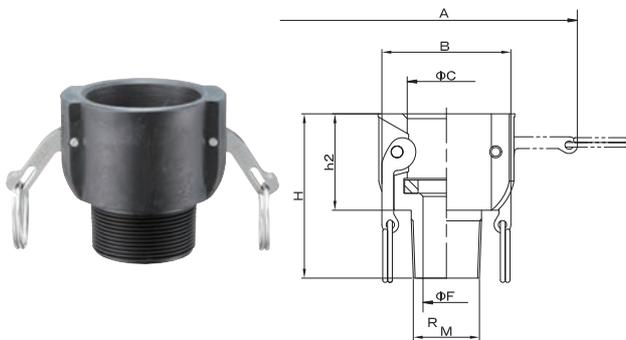


呼び径	mm	20	25	32	40	50	80
	inch	3/4	1	1 1/4	1 1/2	2	3
M		3/4B	1B	1 1/4B	1 1/2B	2B	3B
A		95	125	175	158	167	242
B		64	65	79	93	106	135
ΦC		33	37	46	54	64	93
ΦF		17	22	31	37	37	71
h		23	33	31	30	30	39
h		57	79	81	82	82	98

単位:mm

OZ-C ホースシャंकカップラー

COUPLER HOSE SHANK

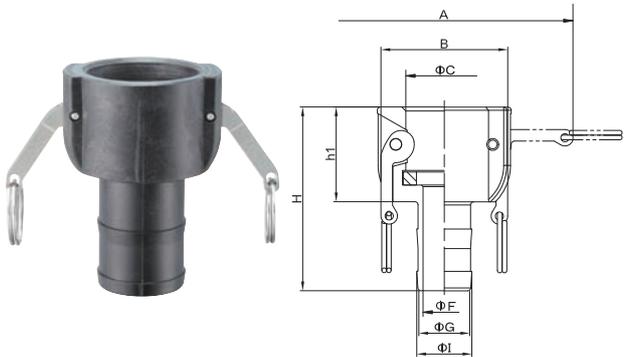


呼び径	mm	20	25	32	40	50	80
	inch	3/4	1	1 1/4	1 1/2	2	3
A		93	125	175	188	198	249
B		64	65	78	89	99	135
ΦC		33	37	46	54	64	93
ΦF		13	21	23	30	41	61
ΦG		19	25	31	37	50	75
ΦI		21	27	33	39	52	79
h		34	47	50	51	56	59
H		75	90	113	122	128	161

単位:mm

OZ-DC ダストキャップ

COUPLER DUST CAP

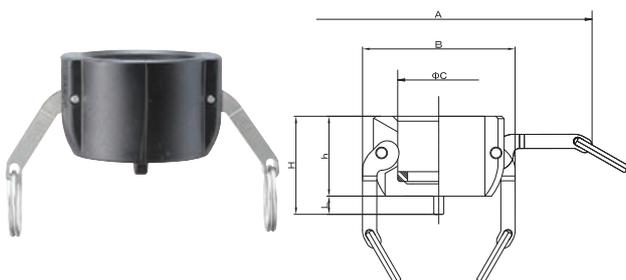

呼び径	mm	20	25	32	40	50	80
	inch	3/4	1	1 1/4	1 1/2	2	3
A		93	125	175	188	198	249
B		64	65	77	89	89	135
ΦC		33	37	46	54	64	93
L		11	14	12	14	13	15
h		34	46	50	51	57	59
H		45	60	62	65	70	74

単位:mm