


Dial Sheet Gauges

0.01mm and 0.05mm


- The sheet gauges can measure wide sheets since the throat depth of this gauges having 300, 500 and 690mm.

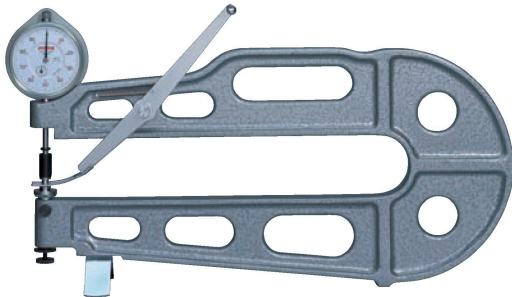

K-1

Graduation: 0.01mm
Range: 0~20mm


- ϕ 10mm flat contact point and ϕ 20mm anvil (Metal)

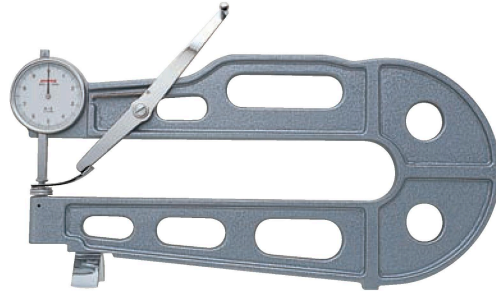

K-2

Graduation: 0.05mm
Range: 0~35mm


- ϕ 20mm flat contact point and anvil (Metal)

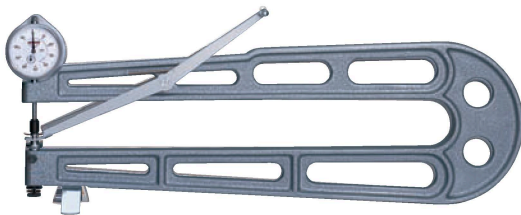

K-3

Graduation: 0.01mm
Range: 0~20mm


- ϕ 10mm flat contact point and ϕ 20mm anvil (Metal)

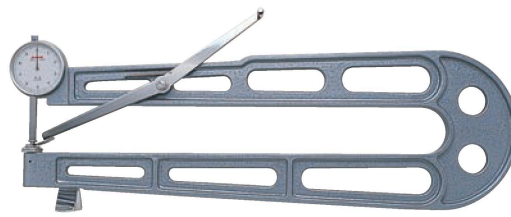

K-4

Graduation: 0.05mm
Range: 0~50mm

- ϕ 25mm flat contact point and anvil (Metal)

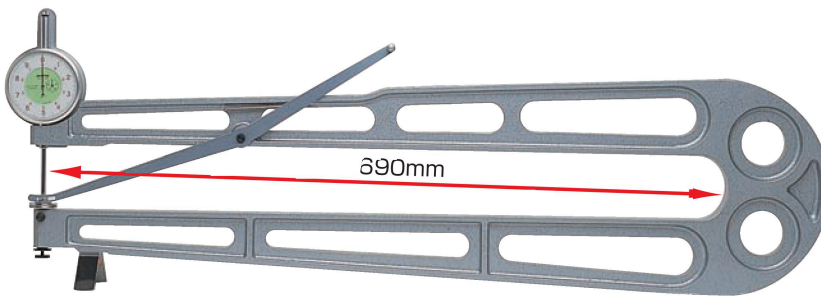


K-7 (Production on request)

Graduation: 0.05mm
Range: 0~50mm

- ϕ 30mm flat contact point and anvil (Metal)

Custom order available

Optional ϕ 30,40 and 50mm contact points and anvils are available. Please specify material for contact point and anvil, either Metal (SK) material or aluminum (AL).

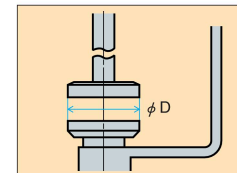

Specifications

Model	Graduation (mm)	Range (mm)	Throat depth (mm)	Accuracy (μ m)	Contact Point		Measuring force less than (N)
					Dia (mm)	Parallelism (μ m)	
K-1	0.01	0~20	300	± 22	10	10	2.0
K-2	0.05	0~35	300	± 100	20	25	3.0
K-3	0.01	0~20	500	± 22	10	10	3.0
K-4	0.05	0~50	500	± 100	25	25	3.0
K-7	0.05	0~50	690	± 100	30	25	3.0

※ Model K-7 is production on request.