


POP Nut Tool Parts List

Marked* : Option

AN500A

AN500A


Thread Size	Mandrel		Nosepiece	
	Part No.	Diameter	Part No.	Hole
M3×0.5	AN500A-04-3	φ3.0	AN500A-05-3H	φ4.0
M4×0.7	AN500A-04-4	φ4.0	AN500A-05-4H	φ4.5
M5×0.8	AN500A-04-5	φ5.0	AN500A-05-5H	φ5.1

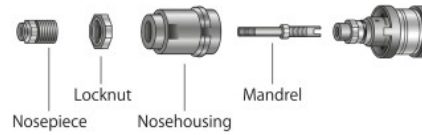

EN600A/EN1000A

EN600A

Thread Size	Mandrel		Nosepiece	
	Part No.	Diameter	Part No.	Hole
M3×0.5	*ENS-M3	φ3.0	*ENS-M3HNP	φ4.0
M4×0.7	ENS-M4	φ4.0	ENS-M4HNP	φ4.5
M5×0.8	ENS-M5	φ5.0	ENS-M5HNP	φ5.1
M6×0.8	ENS-M6	φ6.0	ENS-M6HNP	φ6.1

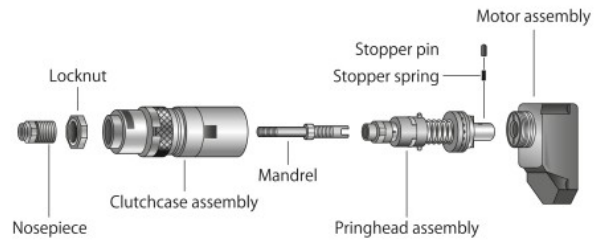

EN1000A

Thread Size	Mandrel		Nosepiece		Stopper spring	
	Part No.	Diameter	Part No.	Hole	Part No.	Coil
M3×0.5	*ENS-M3	φ3.0	*ENS-M3HNP	φ4.0	*EN-1000A-26	6
M4×0.7	*ENS-M4	φ4.0	*ENS-M4HNP	φ4.5		
M5×0.8	*ENS-M5	φ5.0	*ENS-M5HNP	φ5.1		
M6×1.0	ENS-M6	φ6.0	ENS-M6HNP	φ6.1	AN500A-25	5
M8×1.25	ENS-M8	φ8.0	ENS-M8HNP	φ8.1		
M10×1.5	ENS-M10	φ10.0	ENS-M10HNP	φ10.1		

MN10A-S

MN10A-S

Thread Size	Mandrel		Mandrel joint	Spring pin	Nosepiece	
	Part No.	Diameter			Part No.	Hole
M3×0.5	*MN10-04-3A	φ3.0	-	-	*MN10-05-3	φ3.1
M4×0.7	MN10-04-4A	φ4.0			MN10-05-4	φ4.1
M5×0.8	MN10-04-5	φ5.0			MN10-05-5	φ5.1
M6×1.0	MN10-04-6	φ6.0			MN10-05-6	φ6.1
M8×1.25	*MN10-04-81	φ8.0			*MN10-05-8	φ8.1
M10×1.5	*MN10-04-101	φ10.0			*MN10-05-10	φ10.1



MN10A-L

MN10A-L

Thread Size	Mandrel		Mandrel joint	Spring pin	Nosepiece	
	Part No.	Diameter			Part No.	Hole
M3×0.5	*MN10-04-3A	φ3.0	MN10-04-82	MN10-04-83	*MN10-05-3	φ3.1
M4×0.7	*MN10-04-4A	φ4.0			MN10-05-4	φ4.1
M5×0.8	*MN10-04-5	φ5.0			MN10-05-5	φ5.1
M6×1.0	MN10-04-6	φ6.0			MN10-05-6	φ6.1
M8×1.25	MN10-04-81	φ8.0			MN10-05-8	φ8.1
M10×1.5	MN10-04-101	φ10.0			MN10-05-10	φ10.1



PNT110

PNT110

Thread Size	Mandrel		Nosepiece	
	Part No.	Diameter	Part No.	Hole
M3×0.5	FAM400-284	φ3.0	FAM400-288	φ3.2
M4×0.7	FAM400-285	φ4.0	FAM400-289	φ4.2
M5×0.8	FAM400-286	φ5.0	FAM400-290	φ5.2
M6×1.0	FAM400-287	φ6.0	FAM400-291	φ6.2



PNT210

PNT210

Thread Size	Mandrel		Nosepiece	
	Part No.	Diameter	Part No.	Hole
M4×0.7	*FAM400-225	φ4.0	*FAM400-228	φ4.2
M5×0.8	*FAM400-224	φ5.0	*FAM400-171	φ5.2
M6×1.8	FAM400-213	φ6.0	FAM400-173	φ6.2
M8×1.25	FAM400-214	φ8.0	FAM400-176	φ8.2
M10×1.5	FAM400-215	φ10.0	FAM400-178	φ10.3
M12×1.75	FAM400-216	φ12.0	FAM400-208	φ12.3

