

Battery-powered Flashing Beacons


PFH

Φ101	CE	RoHS 10
IP55	Indoor/Outdoor Use	Upright/Sideways Mounting
Ambient Temperature -10°C~+50°C	Red, Amber	Flash Battery




Dimensions (mm)

Side view

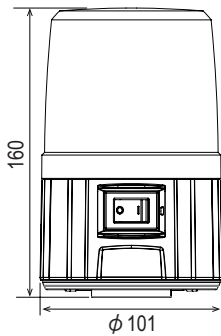

Bottom view

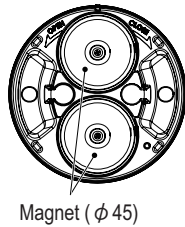


Small Rotating Beacons

SKH-EA


Φ100 mm	CE	RoHS 10	IP23
Indoor/Outdoor Use	Upright/Sideways*/Inverted* Mounting	Ambient Temperature -30°C~+80°C (DC)	Ambient Temperature -30°C~+60°C (AC)
Red, Amber, Green, Blue	Motorized Rotation		



Dimensions (mm)

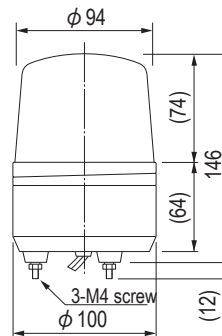

Installation Dimension Drawings

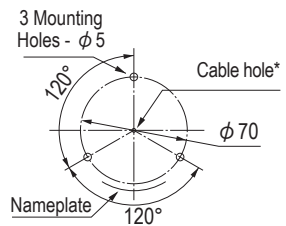

*To pass a 100V plug a Φ30 cable hole is required.

Product List

Model Number	Power Supply	Luminous Color	Mass
PFH-BT-R/Y	4 AA alkaline or nickel metal hydride batteries	Red/Amber	0.51 kg (without batteries)

- Toggle between "Flash pattern" and "Lighting mode" depending on your application: Indoors, outdoors, day or night.

High visibility
Power mode

Battery life (24 h) *




Long-lasting
Eco Mode

Battery life (100 h) *



* Battery life will vary depending on battery type and environmental conditions.

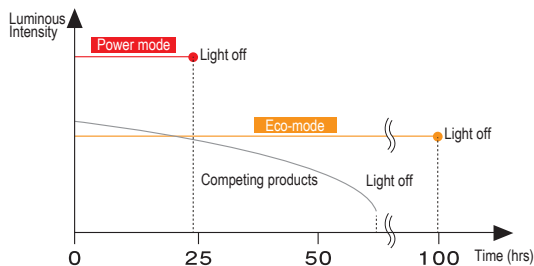

As the battery wears out the light will not dim but visibility and brightness are maintained until the end.

Product List

Model Number	Rated Voltage	Bulb	No.	Luminous Color	Power Consumption	Mass
SKH-12EA-R/Y/G/B	12V DC	12V 10W	9	Red/ Amber/ Green/Blue	9.6W	0.4kg
SKH-24EA-R/Y/G/B	24V DC	24V 10W	10	Red/ Amber/ Green/Blue	12.0W	0.4kg
SKH-100EA-R/Y/G/B	100V AC	12V 5W	12	Red/ Amber/ Green/Blue	6.2W	0.6kg
SKH-200EA-R/Y/G/B	200V AC	12V 5W	12	Red/ Amber/ Green/Blue	6.5W	0.6kg

Bulb shape...Halogen bulb cap BA15S

Bulb No.	Model Number
9	D01201003A-F1
10	D02401003A-F1
12	D01200503A-F1

Optional Parts

For details refer to P. 93 to P. 98

Product Description	Model Number
Wall Mount Bracket	SZ-007