

BSV

Voice Annunciator



87 dB at 1m

15 Channels (Binary)

63 Seconds

IP54

□ 75

NPN/PNP
Open-collector




The unbelievably thin design includes space-saving for equipment.

FEATURES

- Sound reduction is made with just one signal input. (When the sound reduction function is used, the number of playback messages is reduced.)
- Diverse operational modes in combination with commands can be setup for the right application.
- The use of the SD card can allow changing messages while out in the field.
- Protection Rating of IP54 (Only for front panel mount attachment).
- Despite the thin shape, it has a maximum output of 87dB (at 1m).
- It complies with Europe's environment-friendly RoHS Directive.
- Can be used with transistor driven inputs. (Either NPN or PNP)
- A compact design with only a thickness of 19.9mm.
- Two installation choices of panel or wall mount.
- The volume control is accessible from the front.
- Listed by Underwriters Laboratories Inc.
- Conforms to the CE requirements.

Easy installation from the front.

With only the need to access the front cover, reduction in labor time and maintenance is simpler with easily removing the front cover for installation and volume adjustment, etc.

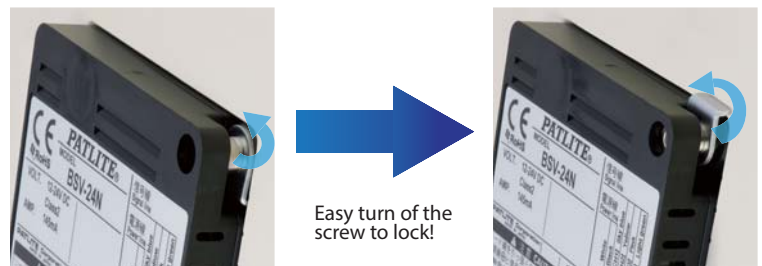

Options

PATLITE Playlist Editor 2
(Free Download)

(OS: Windows® 2000/XP/Vista/Windows 7/Windows 8)

- > The new PATLITE Playlist Editor 2 is required to change the audio message data for this product.
- > The SD Card does not contain any data.

SD Card
(2 GB)
SDV-2GP

