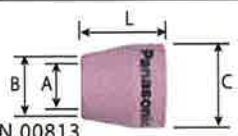

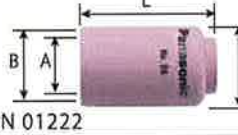

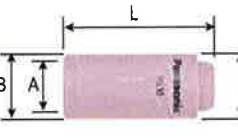
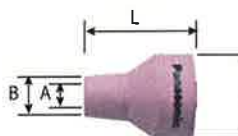
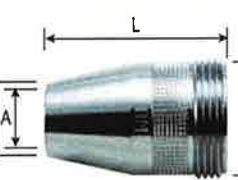


# ノズル

## Nozzles

外形 (代表例) Shape (examples)	電 流 Current	部品コード Parts code	A 内径 mm	B/C 外径 mm	L 全長 mm	No.	主な適用トーチ Applicable Torch	
							レッドティグトーチ Red TIG Torch	8型トーチ Type 8(Model 8)
 TGN 00813	80 A用	<b>TGN 00813</b>	8	12/16	16	No.5K	YT-08TS□	YT-088T YT-088TF YT-188TW
 TGN 00819	120 A用 ? 200 A用	<b>TGN 00618</b>	6.4	11/15	29.5	No.4A	YT-12TS□ YT-12TS1TAB YT-12TP□ YT-20TSW□	YT-128T YT-128TF YT-128TP YT-128TT1
		<b>TGN 00819</b>	8.0	12.7/15	29.5	No.5A		
		<b>TGN 00911</b>	10	14.3	29.5	No.6A		
		<b>TGN 01110</b>	11	16	29.5	No.7A		
		<b>TGN 01222</b>	12.7	17.5	29.5	No.8A		
 TGN 01677		<b>TGN 01677</b>	16	20.6	29.5	No.10A		YT-208TW YT-208TFPW
 TGN 00815	150 A用 ? 300 A用	<b>TGN 00614</b>	6.5	11/17.2	47	No.4	YT-15TS□(C1) YT-15TS□TAB YT-15TS□TAC YT-15TSF□(C1) YT-15TP□ YT-15TS□TAD YT-20TS□(C1) YT-20TSF□(C1) YT-20TS□TAG(TAH) YT-30TS2(C1) YT-30TS2TAG(TAH) YT-30TSW□(C1) YT-30TPW□ YT-30TSW□TAG(TAH) YT-20TS□TAD	YT-158T YT-158TF YT-158TP YT-158TK1
		<b>TGN 00815</b>	8.0	12.6/17.2	47	No.5		
		<b>TGN 00907</b>	9.5	14/17.2	47	No.6		
		<b>TGN 01104</b>	11.0	15.8/17.2	47	No.7		
		<b>TGN 01220</b>	12.7	17.2	47	No.8		
		<b>TGN 01674</b>	16	20.8	47	No.10		
 TGN 01934		<b>TGN 01934</b>	19	24	50	No.12		YT-308TW YT-308TPW
 TGN 00817	500 A用	<b>TGN 00817</b>	8	12/25.5	32	セラミック No.5C	YT-50TSW□(C1)	YT-508TW
		<b>TGN 01107</b>	11	16/25.5	32	セラミック No.7C		
		<b>TGN 01221</b>	12.7	17.5/25.5	32	セラミック No.8C		
 TGN 01219	500 A用	<b>TGN 00909</b>	9.5	14.5/26.4	43	メタル No.6M	YT-50TSW□(C1)	YT-508TW
		<b>TGN 01219</b>	12.7	17.7/26.4	43	メタル No.8M		
		<b>TGN 01673</b>	16	21/26.4	43	メタル No.10M		
		<b>TGN 01933</b>	19	24/26.4	43	メタル No.12M		

□は1型、2型トーチ対応