


12226-82x0-00 xx

**mini Camera Link
SDR Board Mount Connector
Right Angle SMT type**

RoHS Compliant

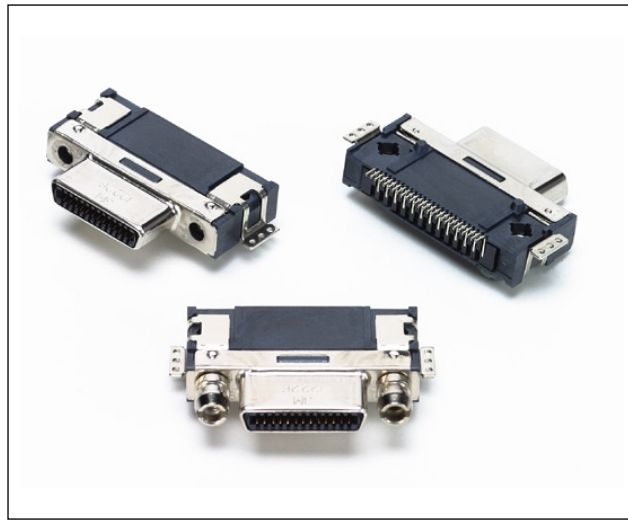

Electrical

Voltage Rating : AC125Vrms
Current Rating : 0.5A
Insulation Resistance : $> 5 \times 10^8$ ohm at 250Vdc
Withstanding Voltage : 350 Vrms for 1 minute

Environmental

Temperature Rating : -40°C to +70°C
Humidity : 90% Max
